

# HyFlex®

ADVANCED MECHANICAL PROTECTION

11-600  
11-605

11-601

Right balance between dexterity and sensitivity for delicate handling



Light Duty



Multi-Purpose

## Right balance between dexterity and sensitivity for delicate handling

- Ansell's HyFlex 11-600, 11-601 and 11-605 industrial gloves are designed for light and delicate applications in dry environments that require high levels of dexterity
- They offer comfortable and exact handling of small objects
- Gloves are offered in 2 colors versions :
  - black and grey for environment that presents a certain level of dirt
  - white for clean environments/dirt sensitive applications



### Industries

- Automotive & Transportation
- Machinery & Equipment
- Maintenance

### Applications

- Handling and assembly of electronic components
- Packaging
- Inspection
- Precision assembly
- Using delicate tools and sensitive instruments

#### Performance Profile


- Stretch nylon liner and polyurethane coating offer tactile sensitivity.
- Available in palm-dipped style for added protection or finger-dipped style for maximum tactile sensitivity.
- Offered in white for dirt sensitive application or in black for environments that present some level of dirt.

#### Performance Standards

HyFlex 11-600 & 11-601



HyFlex 11-605

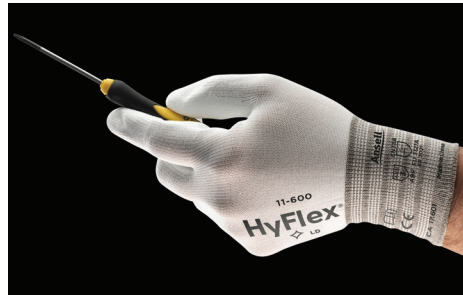

#### Specifications

BRAND   STYLE	DESCRIPTION	GAUGE	SIZE	LENGTH	COLOR	PACKAGE
HyFlex 11-600	Type: Palm coated Coating material: Polyurethane	15	5-11	200-260 mm 7.87-10.23 inches	White	12 pairs/bag, 12 bags/carton
HyFlex 11-601	Liner material: Nylon Cuff style: Knitwrist				Grey and black	
HyFlex 11-605	Type: Fingertip coated Coating material: Polyurethane Liner material: Nylon Cuff style: Knitwrist		6-10	195-230 mm 7.67-9.05 inches	White	

#### Europe, Middle East & Africa

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
+32 2 528 74 00  
+32 2 528 74 01

#### North America

Ansell Healthcare Products, LLC  
111 Wood Avenue South  
Suite 210  
Iselin, NJ 08830, USA  
+1 800 800 0444  
+1 800 800 0445

#### Australia

Ansell Limited  
Level 3, 678 Victoria Street,  
Richmond, Vic, 3121  
Australia  
+61 1800 337 041  
+61 1800 803 578

#### Asia Pacific

Ansell Global Trading Center  
(Malaysia) Sdn Bhd  
Prima 6, Prima Avenue  
Block 3512, Jalan Teknokrat 6  
63000 Cyberjaya  
Selangor, Malaysia  
T: +60 3 83106688  
F: +60 3 8318 6699

#### Latin America & Caribbean

Ansell Brazil Ltda.  
Rua das Figueiras 474 - 4º Andar  
Bairro Jardim  
SP 09080-300 Santo André  
Brazil  
CNPJ: 03.496.778/0001-21  
+55 11 3356 3100

#### Russia

Анселл РУС  
123610 Россия, Москва  
Краснопресненская  
Наб. 12, п.3, оф. 1304А  
Тел. +7 495 258 13 16

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. © 2016 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.