


RED BRASS

90° ELBOW

Features

- 125 Class
- 100% Inspected and tested
- Max pressure 125 PSI
- Temperature -20° to 400°F

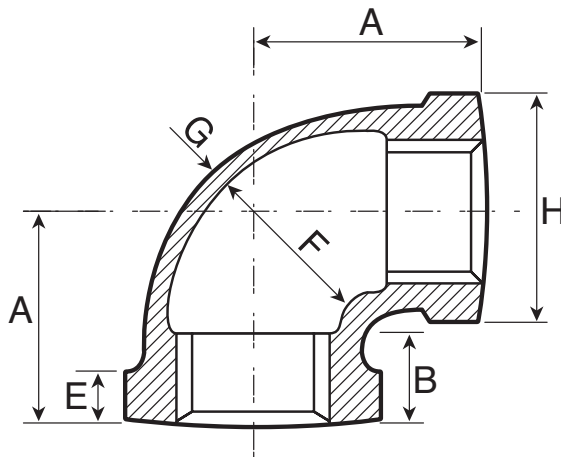

Part No.	Size	
1VER5	1/8"	Threaded
1VER6	1/4"	Threaded
1VER7	3/8"	Threaded
1VER8	1/2"	Threaded
1VER9	3/4"	Threaded
1VEU1	1"	Threaded
1VEU2	1-1/4"	Threaded
1VEU3	1-1/2"	Threaded
1VEU4	2"	Threaded
2CFJ3	2-1/2"	Threaded
2CFJ4	3"	Threaded
2CFJ5	4"	Threaded

- Bronze material meets ANSI/ASTM B62 standard
- Dimensions meet ANSI/ASME B16.15-1985 standard
- Threads meet ANSI B1.20.1

Dimensions are in inches

Part No.	Size	A	B	E	F min	F max	G	H
1VER5	1/8"	0.54	0.25	0.14	0.41	0.44	0.08	0.67
1VER6	1/4"	0.71	0.32	0.16	0.54	0.58	0.08	0.81
1VER7	3/8"	0.82	0.36	0.17	0.68	0.72	0.09	1.00
1VER8	1/2"	1.01	0.43	0.19	0.84	0.90	0.09	1.17
1VER9	3/4"	1.18	0.50	0.23	1.05	1.11	0.10	1.42
1VEU1	1"	1.43	0.58	0.27	1.32	1.39	0.11	1.72
1VEU2	1-1/4"	1.69	0.67	0.31	1.66	1.73	0.12	2.10
1VEU3	1-1/2"	1.84	0.70	0.34	1.90	1.97	0.13	2.38
1VEU4	2"	2.12	0.75	0.41	2.38	2.45	0.15	2.92
2CFJ3	2-1/2"	2.72	0.93	0.49	2.88	2.98	.16	3.50
2CFJ4	3"	3.07	1.00	0.57	3.50	3.60	0.18	4.25
2CFJ5	4"	3.78	1.10	0.69	4.50	4.60	0.22	5.35