

Circuit Guard®, Specification Grade Duplex Receptacles




15A 125V
NEMA 5-15R
UL CSA




20A 125V
NEMA 5-20R
UL CSA


Description	Color	Catalog Number	
Surge protection receptacles with light, 240 joules, 15kA peak current.	Blue	HBL5260SA	HBL5360SA
	Ivory	HBL5260ISA	HBL5360ISA
	Office White	HBL5260OWSA	HBL5360OWSA
	White	HBL5260WSA	HBL5360WSA
Surge protection receptacles with light and alarm, 240 joules, 15kA peak current.	Blue	HBL5262SA	HBL5362SA
	Gray	HBL5262GYSA	HBL5362GYSA
	Ivory	HBL5262ISA	HBL5362ISA
	Office White	HBL5262OWSA	HBL5362OWSA
	White	HBL5262WSA	HBL5362WSA
Isolated ground, surge protection receptacles with light and alarm, 240 joules, 15kA peak current.	Blue	IG5262SA	IG5362SA
	Gray	IG5262GYSA	IG5362GYSA
	Ivory	IG5262ISA	IG5362ISA
	Office White	IG5262OWSA	IG5362OWSA
	Orange	IG5262OSA	IG5362OSA
White	IG5262WSA	IG5362WSA	
4-PLEX® surge protection receptacles with lights, 80 joules, 6.5kA peak current.	Blue	HBL415S	HBL420S
	Ivory	HBL415IS	HBL420IS

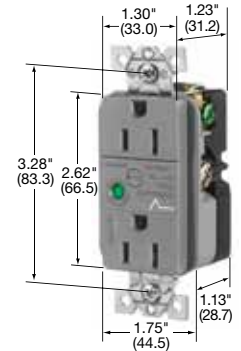

HBL5262GYSA

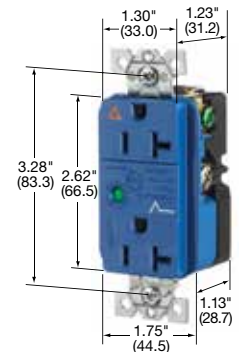

IG5362SA

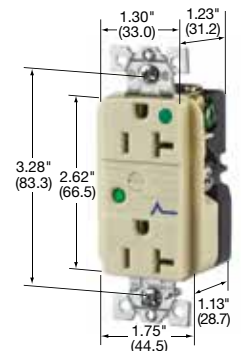

HBL8362ISA

Circuit Guard®, Hospital Grade Duplex Receptacles


Description	Color	Catalog Number	
Surge protection receptacles with light and alarm, 240 joules, 15kA peak current.	Blue	HBL8262SA	HBL8362SA
	Gray	HBL8262GYSA	HBL8362GYSA
	Ivory	HBL8262ISA	HBL8362ISA
	Red	HBL8262RSA	HBL8362RSA
	White	HBL8262WSA	HBL8362WSA
Isolated ground, surge protection receptacles with light and alarm, 240 joules, 15kA peak current.	Blue	IG8262SA	IG8362SA
	Gray	IG8262GYSA	IG8362GYSA
	Ivory	IG8262ISA	IG8362ISA
	Orange	IG8262OSA	IG8362OSA
	Red	IG8262RSA	IG8362RSA
White	IG8262WSA	IG8362WSA	
4-PLEX surge protection receptacles with lights, 80 joules, 6.5kA peak current.	Blue	—	HBL420HS
	Ivory	—	HBL420HIS
	Red	—	HBL420HRS

4-PLEX® Accessories


Description	Color	Catalog Number
4-PLEX adapter plates for 1- and 2-gang (4-PLEX mount directly to 4" (101.6) square device boxes).	Blue	HBL4APBL
	Ivory	HBL4API
	Red	HBL4APR
4-PLEX portable box. Portable 4" (101.6) square box with one cord grip. Accepts up to .66" (16.8) dia. cord.	Ivory	HBL4PBI

Note: 4-PLEX box is not UL Listed.

Wallplates (Sold Separately)

Configuration	High-Impact Thermoplastic			Plated Steel	Stainless Steel (S/S) Brass		
	Color	Standard	Mid-Size				
 1-Gang	Blue	—	PJ26BL	Chrome Brass Plated	SCH26 SBP26	Smooth S/S	SS26
	Gray	P26GY	PJ26GY			Smooth S/S	SSJ26 ▲
	Ivory	P26I	PJ26I			Smooth Brass	SB26
	Ivory	—	PJ26C*				
	Orange	P26OIG**	—				
	Red	P26R	PJ26R				
	White	P26W	PJ26W				

Note: *Premarked "COMPUTER ONLY." Lettering is block 1/4" high.
 **Premarked "ISOLATED GROUND." Lettering is block 1/4" high.
 ▲ Jumbo size plate.
 See section O for additional wallplates.

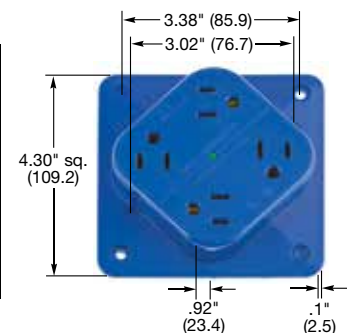

HBL415S

Dimensions in Inches (mm)