

# 2200 Series

## FABRIC PREMIUM

MODEL 2207 SHOWN  
 Scotchgard



### SPECS:

- Features 18-gauge 7/8" round tubular frame
- Two U-shaped double riveted cross braces
- Powder-coated frame
- Double hinges on each side for added stability and durability
- Color coordinated V-tip plugs for added stability
- Color coordinated polypropylene glides
- Features our unique full size double contoured back and waterfall seat
- Scotchguarded fabric is rated to 30,000 double rubs
- Fabric and Foam are Cal 117 rated
- Institutional grade fabric over 1 1/4", 0.9lb. density foam seat and 1.2lb. density back

### DIMENSIONS:

**OVERALL: 29 1/2"H X 18 3/4"W X 20 1/4"D**

FOLDED: 38"H X 18 3/4"W X 2 1/2"D


SEAT: 17 3/4"H X 16"W X 16"D

BACK: 8 3/4"H X 18 3/4"W

### FABRIC / FRAME COMBINATIONS


- #2201** CAFE BEIGE FABRIC / BEIGE FRAME
- #2202** GREYSTONE FABRIC / GREY FRAME
- #2204** IMPERIAL BLUE FABRIC / CHAR-BLUE FRAME
- #2205** IMPERIAL BLUE FABRIC / GREY FRAME
- #2207** RUSSET WALNUT FABRIC / BROWN FRAME
- #2208** MAJESTIC CABERNET FABRIC / GREY FRAME
- #2210** BLACK FABRIC / BLACK FRAME

NON-MARRING REPLACEABLE GLIDES THAT MATCH FRAME COLOR

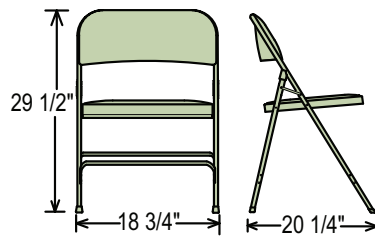

**NEW**
 
### AVAILABLE ACCESSORIES



products meet or exceed applicable ANSI/BIFMA standards

**NEW FABRIC & FRAME COMBO FOR 2012**

**CAL-117 RATED**

### USE WITH:

**Model #84**  
 Double-Tier Hanging Chair Truck

**CAPACITY:** HOLDS UP TO 84 FOLDING CHAIRS (2200 SERIES)

**Model #DY35/#DY50**  
 Folding Chair Dolly

**CAPACITY:** DY35 HOLDS UP TO 35 FOLDING CHAIRS (2200 SERIES)  
 DY50 HOLDS UP TO 50 FOLDING CHAIRS (2200 SERIES)

FOR VERTICAL FOLDING STORAGE



**National Public Seating**



**480lb. weight capacity!**