



**MCR  
SAFETY**

# 1900

## Bull's Eye

### Leather Palm

#### Specification Sheet

#### **PRODUCT DESCRIPTION:**

Aiming for safety? You hit the Bull's eye! Sewn with super-strong, heat resistant DuPont™ Kevlar® thread, these gloves give you protection that is dead on. Premium split side leather provides you excellent abrasion protection. Blue with black and yellow striped fabric.

#### **FEATURES:**

- Premium split side leather
- Sewn with super-strong, heat resistant DuPont™ Kevlar® thread
- Full featured gunn pattern
- Durable 2.75" rubberized safety cuff

#### **APPLICATIONS:**

Automotive Assembly, Utilities, Farming, Iron work , Mining, Pipe fitting, Stamping, Steel Work



#### **TECHNICAL DATA FOR: 1900**

Series	Bull's Eye
Material Group	Leather
Product Type	Leather Palm
Glove Size	Large
Material	Leather
Leather Cut	Split Side
Leather Type	Cow Skin
Grade	Premium
Features	Sewn With KEVLAR
Lining	Fleece Palm
Pattern	Gunn
Thumb Style	Wing
Thickness	1.1 - 1.6 mm




**MCR**  
**SAFETY**

# 1900

## Bull's Eye

### Leather Palm

#### Specification Sheet

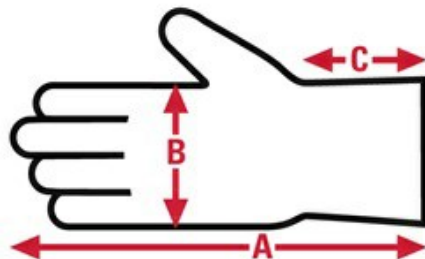

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
1900M	Medium	10.36	6.63	2.75	37.062 lb.	6.177
1900L	Large	10.78	6.55	2.75	42.138 lb.	7.023
1900XL	X - Large	10.95	7.05	2.75	45.714 lb.	7.619

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2018 MCR Safety - All Rights Reserved