




OLD WORK NON-METALLIC CABLE BOXES

Old Work Cable Boxes - For Nonmetallic Sheathed Cable
Two-gang, 2-3/4 in. Deep, 25.0 Cu. in., Flush Mount

A78

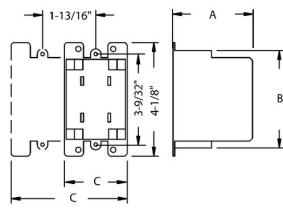

Catalog #: 7488RAC

APPLICATIONS

RACO® Nonmetallic cable boxes are used in branch circuit wiring to splice wires
Accommodates wiring devices such as switches and receptacles
Provide excellent protection for wiring system or devices

PRODUCT FEATURES

RACO® Nonmetallic cable boxes provide the installer with a cost alternative that is lightweight and easy to install
Self-clamping wire entry clamps
Extra long, metal swing arms ensure installation

UL LISTED

File E195963

COMPLIANCES

Boxes are listed for Applications (Electrical Codes), UL Green Book
Boxes are listed for mechanical properties, including the 2-hour Fire Rating, (building codes) UL Orange Book
Federal Manufacturer's number 28488

FIRE RESISTANCE

2-hour fire rating, UL Orange Book

US PATENTS

4,183,486; 4,874,905; 4,580,689; 4,666,599

OTHER PATENTS

Canada 1,237,515; 1,260,599

GENERAL PRODUCT INFORMATION

Wiring System: Nonmetallic Sheathed Cable
Color: Gray

RECOMMENDED MAX LOAD

Fixture (Static) Lbs.: ---

CONFIGURATION

Cable Clamps: 6

DRAWING DIMENSIONS

Dimension A: 2-3/4 in.
Dimension C: 3 in.

PRODUCT MEASUREMENTS

Depth: 2-3/4 in.
Cubic Inches (cm3): 25.0 (409.6)
Wt. Ea. (Lbs.): 0.272
Product Length (in.): 2.75
Product Width (in.): 4.13
Product Height (in.): 3.00

PACKAGING

Minimum Pack Qty.: 30
Std. Pkg.: 30
Product UPC-A Labeled: Yes
Weight (Lbs. Per/C): 27.20
Ship Carton Length (in.): 24.00
Ship Carton Width (in.): 8.00

Ship Carton Height (in.):	16.00
Ctn Weight (Lbs.):	8.16
Pallet Qty:	750
UPC Number:	050169974889
I2of5:	50050169974884