

ACTIVARMR®

PERSONAL PROTECTIVE GEAR

80-400

Hi-Viz™ insulated glove

Previously known as: Powerflex® 80-400



Cold



Medium Duty

Excellent insulation and comfortable handling in cold conditions

- Ansell's ActivArmr 80-400 glove is a general purpose glove designed to provide outstanding insulation from cold conditions and high levels of comfort and grip
- This glove combines a thermal terry loop acrylic liner with a naturally insulating latex coating, ensuring excellent insulation against the cold. The glove provides comfort and protection for the wearer in temperatures as low as $-15^{\circ}\text{C}/5^{\circ}\text{F}$ (extended contact) and $-30^{\circ}\text{C}/-22^{\circ}\text{F}$ (intermittent or short contact)
- With a bright yellow terry loop acrylic liner, the ActivArmr 80-400 glove offers extra high-visibility in low or poor light conditions. This extra visibility brings additional safety for external workers when it's getting dark



Industries

- Construction
- Forestry

Applications

- Shipping and loading of product
- Construction
- Outdoor Winter Use

ACTIVARMR®

PERSONAL PROTECTIVE GEAR

80-400

Hi-Viz™ insulated glove


Previously known as: Powerflex® 80-400

Key Features

- High visibility with seamless yellow thermal terry liner
- Bright blue crinkled palm provides added wet and dry grip
- Insulated glove for use in cold temperatures
- Ergonomic design for superior fit, comfort, flexibility and dexterity
- Also offers protection when handling hot parts up to 250°C / 480°F for 15 seconds

Performance Standards & Regulatory Compliance

REACH Compliant

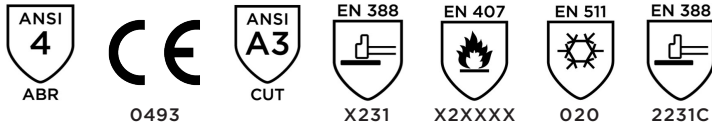

Specifications

| BRAND STYLE | DESCRIPTION | Gauge | SIZE | LENGTH | COLOR | PACKAGE |
|------------------|---|-------|-----------------|----------------------|-------|---|
| ActivArm® 80-400 | Finishing: Palm Coated Coating Material: Natural Latex Rubber Liner Material: Acrylic Terry Loop Cuff Style: Knitwrist | 7 | 7, 8, 9, 10, 11 | 250 - 290 mm, 10-12" | Blue | • 12 pairs in a bag; 6 bags in a carton |

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Australia

Ansell Limited
Level 3, 678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalin Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306,
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.