




15 and 20 Ampere, 125 Volts

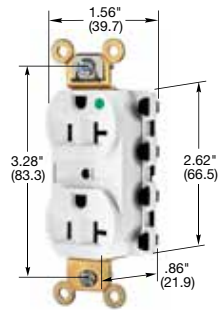


SNAP8300WA

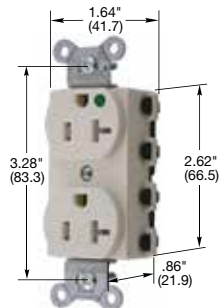


SNAP8300LATR

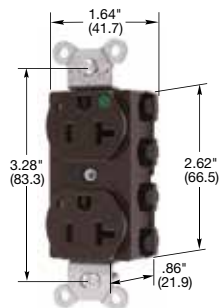

SNAP8300L

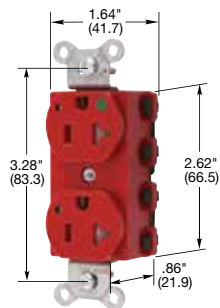

SNAP8300RLTR

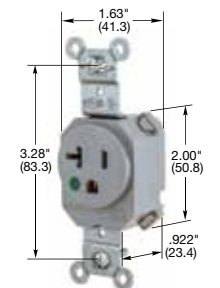

SNAP8310GY

Dimensions in Inches (mm)

IP20
SUITABILITY



15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

SNAPConnect® Extra Heavy Duty Hospital Grade ● Receptacles

Duplex

Hospital grade, finder groove, nylon face, modular receptacle which requires pigtailed connector on page M-5.

Hospital grade, smooth nylon face, modular receptacle which requires pigtailed connector on page M-5. Assembled in USA.



Hospital grade, Tamper-Resistant, smooth nylon face, modular receptacle which requires pigtailed connector on page M-5. Assembled in USA.



Hospital grade, Tamper-Resistant, Split Circuit, smooth nylon face, modular receptacle which requires pigtailed connector on page M-5. Assembled in USA.



Isolated ground^A, Hospital grade, Tamper-Resistant.

Hospital grade, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page M-5. Assembled in USA.



Isolated ground^A, Hospital grade, with Power Indicating LED.

Hospital grade, Tamper-Resistant, with Power Indicating LED, smooth nylon face, modular receptacle which requires pigtailed connector on page M-5. Assembled in USA.

Isolated ground^A, Hospital grade, TR with Power Indicating LED.

	Color	Catalog Number	
	Black	SNAP8200BKA	SNAP8300BKA
	Brown	SNAP8200A	SNAP8300A
	Gray	SNAP8200GYA	SNAP8300GYA
	Ivory	SNAP8200IA	SNAP8300IA
	Light Almond	SNAP8200LAA	SNAP8300LAA
	Red	SNAP8200RA	SNAP8300RA
	White	SNAP8200WA	SNAP8300WA
	Black	SNAP8200BKNA	SNAP8300BKNA
	Brown	SNAP8200NA	SNAP8300NA
	Gray	SNAP8200GYNA	SNAP8300GYNA
	Ivory	SNAP8200INA	SNAP8300INA
	Light Almond	SNAP8200LANA	SNAP8300LANA
	Red	SNAP8200RNA	SNAP8300RNA
	White	SNAP8200WNA	SNAP8300WNA
	Black	SNAP8200BKTRA	SNAP8300BKTRA
	Brown	SNAP8200TRA	SNAP8300TRA
	Gray	SNAP8200GYTRA	SNAP8300GYTRA
	Ivory	SNAP8200ITRA	SNAP8300ITRA
	Light Almond	SNAP8200LATRA	SNAP8300LATRA
	Red	SNAP8200RTRA	SNAP8300RTRA
	White	SNAP8200WTRA	SNAP8300WTRA
	Black	SNAP8200BKSCTRA	SNAP8300BKSCTRA
	Brown	SNAP8200SCTRA	SNAP8300SCTRA
	Gray	SNAP8200GYSCTRA	SNAP8300GYSCTRA
	Ivory	SNAP8200ISCTRA	SNAP8300ISCTRA
	Light Almond	SNAP8200LASCTRA	SNAP8300LASCTRA
	Red	SNAP8200RSCTRA	SNAP8300RSCTRA
	White	SNAP8200WSCTRA	SNAP8300WSCTRA
	Orange	SNAP8200IGTRA	SNAP8300IGTRA
	Red	SNAP8200RIGTRA	SNAP8300RIGTRA
	Black	SNAP8200BKL	SNAP8300BKL
	Brown	SNAP8200L	SNAP8300L
	Gray	SNAP8200GYL	SNAP8300GYL
	Ivory	SNAP8200IL	SNAP8300IL
	Light Almond	SNAP8200LAL	SNAP8300LAL
	Red	SNAP8200RL	SNAP8300RL
	White	SNAP8200WL	SNAP8300WL
	Orange	SNAP8200IGL	SNAP8300IGL
	Red	SNAP8200RIGL	SNAP8300RIGL
	Black	SNAP8200BKLTRA	SNAP8300BKLTRA
	Brown	SNAP8200LTRA	SNAP8300LTRA
	Gray	SNAP8200GYLTRA	SNAP8300GYLTRA
	Ivory	SNAP8200ILTRA	SNAP8300ILTRA
	Light Almond	SNAP8200LALTRA	SNAP8300LALTRA
	Red	SNAP8200RLTRA	SNAP8300RLTRA
	White	SNAP8200WLTRA	SNAP8300WLTRA
	Orange	SNAP8200IGLTRA	SNAP8300IGLTRA
	Red	SNAP8200RIGLTRA	SNAP8300RIGLTRA

SNAPConnect® Extra Heavy Duty Hospital Grade ● Single Receptacles

Color	Hospital Grade ●		Hospital Grade ● Tamper-Resistant		
	15A 125V	20A 125V	15A 125V	20A 125V	
Black	SNAP8210BK	SNAP8310BK	SNAP8210BKTR	SNAP8310BKTR	
Blue	SNAP8210BL	SNAP8310BL	SNAP8210BLTR	SNAP8310BLTR	
Brown	SNAP8210	SNAP8310	SNAP8210TR	SNAP8310TR	
Gray	SNAP8210GY	SNAP8310GY	SNAP8210GYTR	SNAP8310GYTR	
Ivory	SNAP8210I	SNAP8310I	SNAP8210ITR	SNAP8310ITR	
Light Almond	SNAP8210LA	SNAP8310LA	SNAP8210LATR	SNAP8310LATR	
Red	SNAP8210R	SNAP8310R	SNAP8210RTR	SNAP8310RTR	
White	SNAP8210W	SNAP8310W	SNAP8210WTR	SNAP8310WTR	