
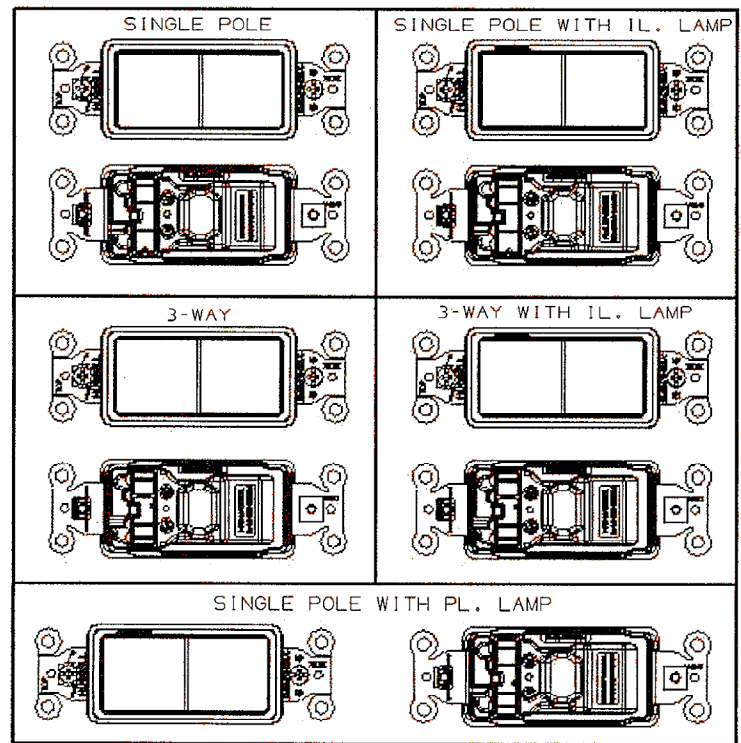


M-11588 4

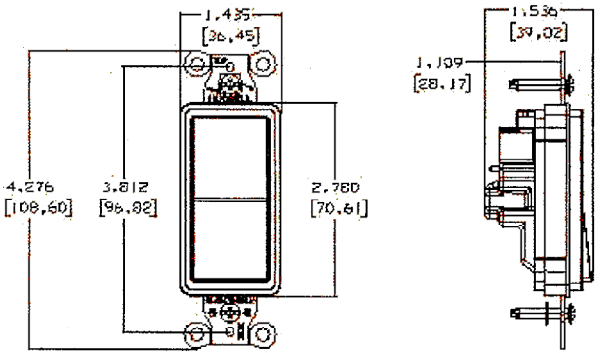

CATALOG NO.	RATING/TYPE	COLOR
SNAP21011*	15A 120-277V, SP	IVORY
SNAP2101W*	15A 120-277V, SP	WHITE
SNAP2101BK*	15A 120-277V, SP	BLACK
SNAP2101BR*	15A 120-277V, SP	BROWN
SNAP2101GY*	15A 120-277V, SP	GRAY
SNAP2101R*	15A 120-277V, SP	RED
SNAP2101LA*	15A 120-277V, SP	LIGHT ALMOND
SNAP2101PLR*	15A 120-277V, SP, PL	RED
SNAP2101PLC*	15A 120-277V, SP, PL	CLEAR
SNAP2101PLI*	15A 120-277V, SP, PL	IVORY
SNAP2101ILBK*	15A 120-277V, SP, PL	BLACK
SNAP2101ILW*	15A 120-277V, SP, PL	WHITE
SNAP2101ILR*	15A 120-277V, SP, IL	RED
SNAP2101ILC*	15A 120-277V, SP, IL	CLEAR
SNAP2101ILI*	15A 120-277V, SP, IL	IVORY
SNAP2101PLBK*	15A 120-277V, SP, IL	BLACK
SNAP2101PLW*	15A 120-277V, SP, IL	WHITE
SNAP21031*	15A 120-277V, 3W	IVORY
SNAP2103W*	15A 120-277V, 3W	WHITE
SNAP2103BK*	15A 120-277V, 3W	BLACK
SNAP2103BR*	15A 120-277V, 3W	BROWN
SNAP2103GY*	15A 120-277V, 3W	GRAY
SNAP2103R*	15A 120-277V, 3W	RED
SNAP2103LA*	15A 120-277V, 3W	LIGHT ALMOND
SNAP2103ILR*	15A 120-277V, 3W, IL	RED
SNAP2103ILC*	15A 120-277V, 3W, IL	CLEAR
SNAP2103ILI*	15A 120-277V, 3W, IL	IVORY
SNAP2103ILBK*	15A 120-277V, 3W, IL	BLACK
SNAP2103ILW*	15A 120-277V, 3W, IL	WHITE
SNAP21211*	20A 120-277V, SP	IVORY
SNAP2121W*	20A 120-277V, SP	WHITE
SNAP2121BK*	20A 120-277V, SP	BLACK
SNAP2121BR*	20A 120-277V, SP	BROWN
SNAP2121GY*	20A 120-277V, SP	GRAY
SNAP2121R*	20A 120-277V, SP	RED
SNAP2121LA*	20A 120-277V, SP	LIGHT ALMOND
SNAP2121PLR*	20A 120-277V, SP, PL	RED
SNAP2121PLBK*	20A 120-277V, SP, PL	BLACK
SNAP2121PLC*	20A 120-277V, SP, PL	CLEAR
SNAP2121PLWNA	20A 120-277V, SP, PL	WHITE
SNAP2121PLI*	20A 120-277V, SP, PL	IVORY
SNAP2121ILR*	20A 120-277V, SP, IL	RED
SNAP2121ILC*	20A 120-277V, SP, IL	CLEAR
SNAP2121ILWNA	20A 120-277V, SP, IL	WHITE
SNAP2121ILI*	20A 120-277V, SP, IL	IVORY
SNAP2121ILBK*	20A 120-277V, SP, IL	BLACK
SNAP21231*	20A 120-277V, 3W	IVORY
SNAP2123W*	20A 120-277V, 3W	WHITE
SNAP2123BK*	20A 120-277V, 3W	BLACK
SNAP2123BR*	20A 120-277V, 3W	BROWN
SNAP2123GY*	20A 120-277V, 3W	GRAY
SNAP2123R*	20A 120-277V, 3W	RED
SNAP2123LA*	20A 120-277V, 3W	LIGHT ALMOND
SNAP2123ILR*	20A 120-277V, 3W, IL	RED
SNAP2123ILW*	20A 120-277V, 3W, IL	WHITE
SNAP2123ILBKNA	20A 120-277V, 3W, IL	BLACK
SNAP2123ILI*	20A 120-277V, 3W, IL	IVORY

NOTE:
 1. BASE COLOR: BLACK
 2. ALL DIMENSIONS ARE IN INCHES AND (MILLIMETERS)
 3. CATALOG NOS. MARKED WITH AN * MAY BE FOLLOWED BY "NA".

LIST OF PARTS		
DESCRIPTION	MATERIAL	FINISH
ROCKER	THERMOPLASTIC	NONE
TOP HOUSING	THERMOPLASTIC	NONE
BASE	THERMOPLASTIC	NONE
RUBBER INSERT	ELASTOMER	NONE
RUBBER BUMPER	ELASTOMER	NONE
DRIVE SCREW	STEEL	ZINC PLATED
MOUNTING SCREW	STEEL	ZINC PLATED
STRAP	STEEL	ZINC PLATED
SPRING	STEEL	NONE
STAPLE	STEEL	NONE
BRUSH	BRASS ALLOY	BRIGHT DIP
SILVER CONTACTOR	CADMIUM FREE SILVER ALLOY	NONE
COMMON TERMINAL	BRASS ALLOY	SILVER PLATED
SP STATIONARY TERM.	BRASS ALLOY	SILVER PLATED
GROUND TERMINAL	BRASS ALLOY	BRIGHT DIP
3W STATIONARY TERM.	BRASS ALLOY	SILVER PLATED
PVC WASHER	PVC PLASTIC	NONE
BRUSH ACTUATOR	STEEL	ZINC PLATED
LAMP WIRE PIN	BRASS ALLOY	NONE
LED LAMP	LED	NONE

4	REMOVE CAT# SNAP2123ILC, ADD CAT#SNAP2121ILBK, SNAP2121ILWNA, SNAP2121PLBK, SNAP2121PLWNA, SNAP2123ILBKNA, SNAP2123ILI; SUFFIX "*" TO CAT#SNAP2101BK, SNAP2121BK, SNAP2107PLW, SNAP2123BK, SNAP2103ILW, SNAP2101ILBK, SNAP2101ILW, SNAP2101PLBK, SNAP2103BK, SNAP2103ILBK; "SILVER PLATED" WAS "BRIGHT DIP" IN THE FINISH COLUMN OF PARTS LIST TABLE PER DCN #19223.	DL	1/31/13
3	TO CAT NOS. ADDED * ADDED NOTE 3. DCN17792		6/27/11
2	ADDED CAT NOS ... 2101ILBK, 2101ILW, 2101PLBK, 2101PLW, 2103ILBK, 2103ILW DCN17501 SRE	SRE	2/28/11
1	RELEASED FOR PRODUCTION PER DCN16897	C.Z	10/3/2010
SYM	REVISONS	APP	DATE

THE DESIGN AND DIMENSIONS OF THE PRODUCT SHOWN ON THIS DRAWING ARE SUBJECT TO CHANGE WITHOUT NOTICE

TITLE
 COMMERCIAL GRADE
 15A & 20A SNAP DECO SWITCH, HUBBELL

TOLERANCES UNLESS OTHERWISE SPECIFIED	WIRING DEVICE-KELLEMS HUBBELL INCORPORATED BRIDGEPORT, CT			
FRACTIONS ±1/64	DR. BY	F.H	APP. BY	C.Z
DECIMALS ±.005	TR. BY		SCALE	
ANGLES ±2°	CHK'D BY	J.X	DATE	03/12/10