




**50%
LESS
EFFORT**

**MORE
POWER**

**CRESCENT
H.K. PORTER®**

Compact Bolt Cutters

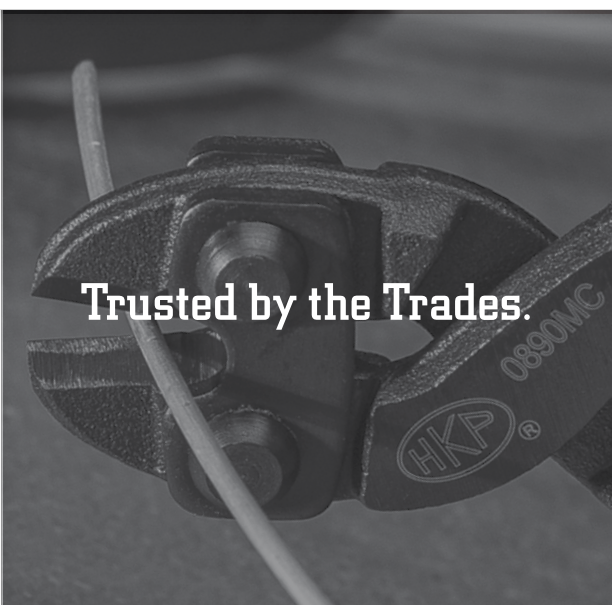

Trusted by the Trades.

Compact cutting power with half the effort of standard Lineman's pliers.

Straight Cutter model has center cut blades for longest life. Angle Cutter model has flush cut blades for trimming close. Both have smooth plastic dipped grips for maximum durability and easy clean-up.

For maximum comfort and minimum fatigue, the Spring Return Straight Cutter features co-molded grips and a durable return spring for repetitive-cut production applications. Its straight head and center cut blades make it fast and easy to use.



CENTER CUT
BLADES

Heavy-duty design for maximum durability

ANGLED CUT
BLADES

Induction-hardened cutting edges for exceptional performance and long life

Recessed throat notch for 50% less cutting effort

Smooth plastic dipped grips wipe clean fast

Cut It Close



Angle Cutter head can be positioned flat against cutting surface for clean, nearly flush cuts, making it perfect for jobs like finish trimming of metal wire fencing.



SPRING
LOADED™

CENTER CUT
BLADES

Robust locking latch is easy to use, even with gloves

Recessed throat notch for 50% less cutting effort

Extra-wide dual-material co-molded grips for superior fit and comfort

Heavy-duty spring returns blades to open position for high production applications

Induction-hardened cutting edges for exceptional performance and long life

50% Less Effort



Every HKP Compact Bolt Cutter has a precision engineered recessed throat notch that holds material closer to joint for maximum leverage and 50% less cutting effort compared to standard Lineman's pliers.

Induction-hardened cutting edges make quick work of the tough stuff.



WIRE
Copper, vinyl coated, steel and aluminum



CHAIN
Light duty, hobby, and craft chain



FASTENERS
Bolts, nails, rivets, and screws



FENCING
Barbed wire, chicken wire, hardware cloth



HARD MATERIALS
Spring steel and piano wire

Cutting Applications and Capacities

Material	Maximum Diameter
SOFT (copper, aluminum, plastics, drop ceiling wire)	.24 inches (6.0 mm)
MEDIUM HARD (nails, rivets, wire pins, light chain)	.20 inches (5.2 mm)
HARD (steel wire, wire rope strands, chicken wire)	.16 inches (4.0 mm)
VERY HARD (spring steel, music/piano wire)	.15 inches (3.8 mm)

Item No	Description	Shelf Pack Quantity	UPC	Shelf Pack Code	Product Package Dimensions	Product Weight
0890MC	COMPACT BOLT/WIRE CUTTER, CENTER CUT	6	37103274540	10037103274547	7.3"L x 2.3"W x 1.4"H	0.8 lbs.
0890MA	COMPACT BOLT/WIRE CUTTER, ANGLE HEAD	6	37103274557	10037103274554	7.3"L x 2.3"W x 1.4"H	0.8 lbs.
0890SMC	COMPACT BOLT/WIRE CUTTER, CENTER CUT, CO-MOLD GRP, SPRING LOADED	6	37103274564	10037103274561	7.3"L x 2.3"W x 1.4"H	0.8 lbs.