


## TECHNICAL DATA SHEET

Part#: 2844D

Pliers - 2 Star Medium Chain Nose - SS - Serrated Jaws  
General purpose applications

The 2844D medium chain nose serrated jaw plier has an overall length is 5.75". It is made of stainless steel and features dual leaf springs for smooth action. It features a ergonomically molded antimicrobial Anti-Static grip (10<sup>10</sup> ohms/sq surface resistivity) with dual leaf springs.

- Precision Level           ★★
- Material                   SS (AISI 440)
- Surface Resistivity       10<sup>10</sup> ohms/sq
- Shape                      Chain Nose
- Tip Size                    .030" x .045" (.75mm x 1.125mm)
- Tip Angle
- Tip Length                1.3"(32.5mm)
- Body Width
- Body Height
- OAL                         5.75" (143.75mm)
- Weight (OZ)              4
- UPC                         662847008740
- Schedule B               8203.20.60.30
- ECCN                      EAR99
- UNSPSC Code           27112148
- Country of Origin       Pakistan
- Group                      Medium Nose

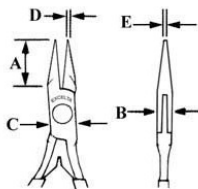

**2844D Chain Nose Pliers**  
**Serrated Jaw**

- A= 1.182"**
- B= .257"**
- C= .375"**
- D= .045"**
- E= .055"**

