



MCR
SAFETY

N96795

Ninja

Hand Protection Specification Sheet

PRODUCT DESCRIPTION:

Memphis Ninja® gloves are engineered to provide the highest level of innovation. Ninja® BNF (Breathable Nitrile Foam) has exceptional abrasion resistance and unparalleled grip performance. This unique polymer achieves outstanding abrasion resistance based on ASTM and CE testing. Our BNF technology provides greater comfort and longer wear due to its excellent breathability by allowing the glove to better dissipate body heat. The N96795 features a nylon/spandex shell, fully coated black BNF, and nitrile dots for greater grip.

FEATURES:

- 15 Gauge Black Nylon/Spandex Shell
- Black Full BNF Coating
- Black Nitrile Dots on the palm
- Knit Wrist

APPLICATIONS:

Agriculture, Assembly Line Production, Automotive Assembly, Baggage Handling, Carpentry, Construction, Furniture industry, Janitorial, Landscaping, Mechanics



TECHNICAL DATA FOR: N96795

Series	Ninja
Product Type	Hand Protection
Glove Size	Large
Gauge	15 Gauge

EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	4
EN 388 : CE Score - Puncture	1
ANSI Puncture	ANSI Puncture 2
ANSI Abrasion	ANSI Abrasion 5




MCR
SAFETY

N96795

Ninja

Hand Protection Specification Sheet

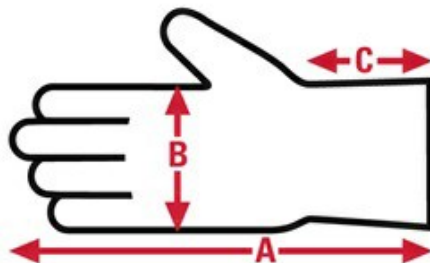

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
N96795L	Large	10.039	5.197	2.756	28.800 lb.	2.400
N96795M	Medium	9.448	5.119	2.559	28.836 lb.	2.403
N96795S	Small	8.859	4.684	2.559	24.140 lb.	2.012
N96795XL	X - Large	10.236	5.354	2.953	31.800 lb.	2.650
N96795XXL	XX - Large	10.629	5.511	3.346	31.008 lb.	2.584

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved