

SpikeShield® Power Quality Products
15A, 125V AC, 2 Pole, 3 Wire Grounding
Surge Protection Receptacles

HUBBELL

Features

- Automatic self-grounding staple
- Distinctive surge symbol provides quick identification
- Power-on indicator light verifies that power is available
- Alert alarm sounds when surge protection is no longer functioning

Ordering Information

Description	Device Color	UPC	Catalog Number
Receptacles with light,	Blue	783585060019	HBL5260SA



Listings

UL Listed File E2186
 Listed to UL Standards 498
 CSA Certified to Specification C22.2 No. 42


Specifications

Face Material	Nylon
Base Material	Nylon
Power Contact	.031" (.8) Brass
Contact Design	Tandem Modified Bypass
Mounting Strap	.050" (1.3) Steel-Zinc Coated

Performance

Electrical	
Protection Modes	Normal and Common Modes
Response Time	Approximately 5 ns
Transient Suppression Voltage	Peak Energy (10 X 100 µs), Peak Current (8 X 20 µs) 120V AC + 10% - 15%

Environmental	
Flammability	UL 94V-2
Operating Temperature	32°F to 140°F (0°C to 60°C)

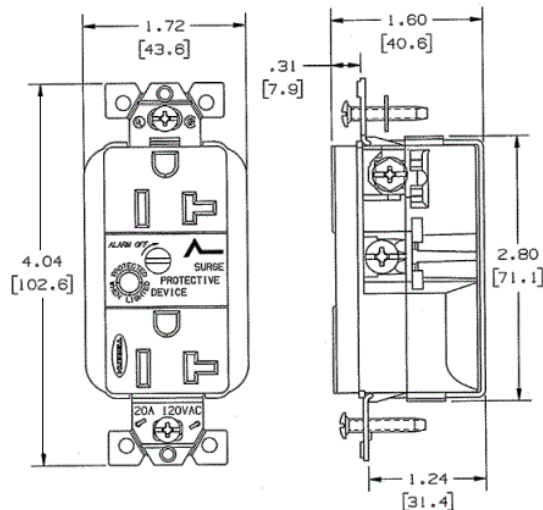

Online Resources

Customer Use Drawing
 eCatalog
 Installation Instructions

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

