

Twist-Lock® Devices  
 50A, 600V AC, 250V DC, 3 Pole, 4 Wire  
 Grounding  
 Receptacle

# HUBBELL

## Features

- Thermoset construction offers high heat resistance
- Armored housing provides superior impact resistance
- One piece contacts provide low operating temperatures

## Ordering Information

Description	Device Color	UPC	Catalog Number
Phenolic	Black	783585237176	HBL7379

## Listings

Listed to UL 498  
 Certified to CSA C22.2 No.42

## Specifications

Body	Phenolic
Face	Phenolic
Contacts	Brass
Terminal Screws	Steel
Insulator	Phenolic

## Performance

### Electrical


Current Interrupting Certified for current interrupting at full rated current  
 Dielectric Voltage Withstands 2,000V minimum

### Mechanical

Terminal Accommodation #10 AWG - #6 AWG solid or stranded copper wire only

### Environmental

Flammability UL 94 V0  
 Operating Temperatures Maximum continuous 75°C; minimum -40°C (w/o impact)

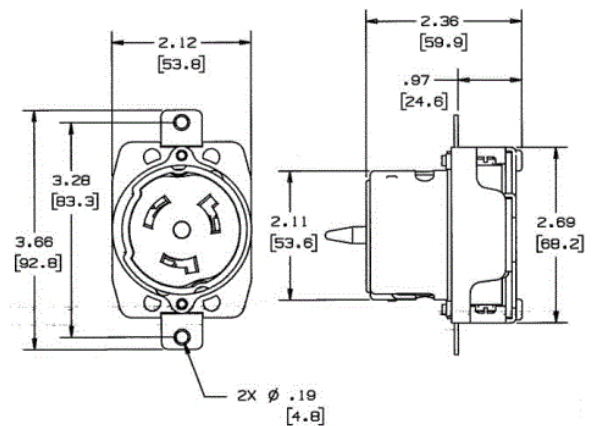

## Accessories

Plug	HBL7765C
Weatherproof Lift Cover	HBL7774WO
Single Gang Stainless Steel Wallplate	SS750
4" Square Raised Cover	HBL50SC

## Resources

Customer Use Drawing  
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

