



Classic® No. 2 200 Amp MIG Gun



60% Duty Cycle - CO₂ Carbon Dioxide
Suitable for Medium Duty Fabrication.

WELDING PROCESSES:
MIG (GMAW), Aluminum (GMAW)

Standard Options Include:

- Rear Connector and Knucklehead™ Flexible Conductor Tube
- Standard Conductor Tube – Part No. 62J-60 (Stock No.1620-1301) on all guns up to 15ft (4.6 m)
- Part No. 62J-45 (Stock No. 1620-1300) on all guns over 15ft (4.6 m)
- Conduit Liner – 42 Series

MIG GUNS

Tweco® Style Rear Connector

Adapter kits are available to fit Tweco rear connection to most wire feeders

Wire Size	Length	Part No.	Stock No.
Up To .035" (0.9 mm)	10 ft (3 m)	210-3035	1020-1111
	12 ft (3.6 m)	212-3035	1020-1112
	15 ft (4.6 m)	215-3035	1020-1113
	20 ft (6.1 m)	220-3035	1020-1114
Up To .045" (1.2 mm)	10 ft (3 m)	210-4045	1020-1121
	12 ft (3.6 m)	212FN-4045	1020-1322
	15 ft (4.6 m)	215-4045	1020-1123
	20 ft (6.1 m)	215-4045K4**	1020-1660
	20 ft (6.1 m)	225-4045	1020-1125

Lincoln® Style Rear Connector

Fits Lincoln LN7, 8, 9, SP200

Wire Size	Length	Part No.	Stock No.
Up To .035" (0.9 mm)	10 ft (3 m)	L210-3035	1020-1140
	12 ft (3.6 m)	L212-3035	1020-1142
	15 ft (4.6 m)	L215-3035	1020-1144

Some Lincoln wire feeders are assembled with their K1500-2 gun receiving bushing that will accept Tweco Style MIG Guns direct from the factory. Control wire Part No. MS354-DSLJ (Stock No. 2060-2137) must be ordered separately.

Euro-Kwik Style Rear Connector

Wire Size	Length	Part No.	Stock No.
Up To .035" (0.9 mm)	10 ft (3 m)	X210-3035	1020-1612
	12 ft (3.6 m)	X212-4045	1020-1622
Up To .045" (1.2 mm)	15 ft (4.6 m)	X215-4045	1020-1623


Miller® Style Rear Connector

Wire Size	Length	Part No.	Stock No.
Up To .035" (0.9 mm)	10 ft (3 m)	M210-3035	1020-1130
	12 ft (3.6 m)	M212-3035	1020-1132
	15 ft (4.6 m)	M215-3035	1020-1134
Up To .045" (1.2 mm)	10 ft (3 m)	M210-4045	1020-1131
	12 ft (3.6 m)	M212-4045	1020-1133
	15 ft (4.6 m)	M215-4045	1020-1135
	15 ft (4.6 m)	M215-4045K4**	1020-1661

Flexible Knucklehead™

Amp/Model	Bend Angle	Stand Cons.	Part No.	Stock No.
No.2	60°	■	62SFLX3-60	1620-1105
	80°	■	62SFLX4-80	1620-1106

** Suffix "K4" = Knucklehead Conductor Tube – Part No. 62SFLX4-80 (Stock No. 1620-1106)

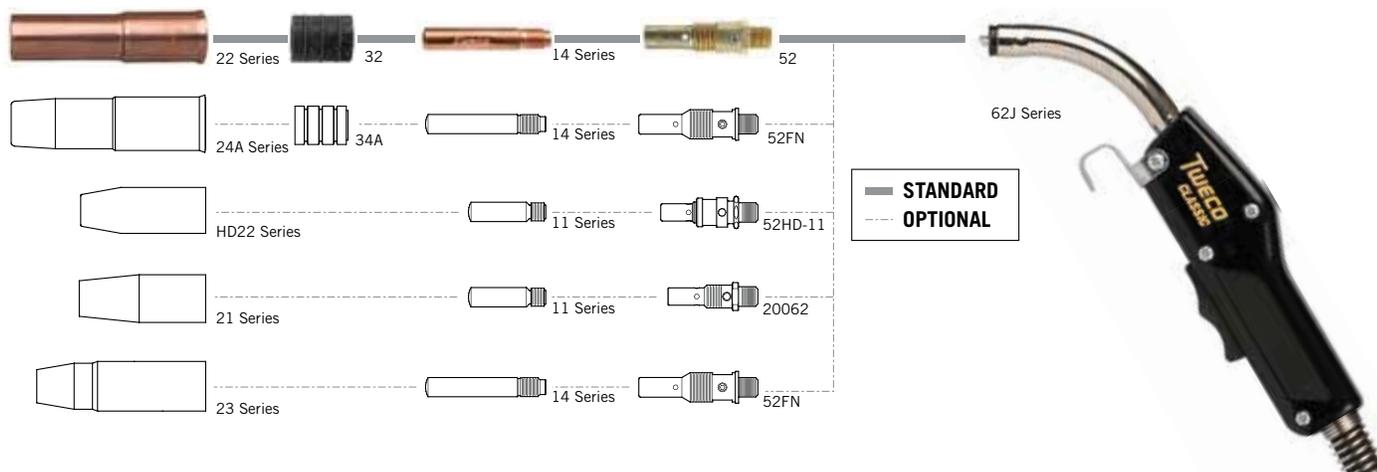

Rated Output			Wire Size	Cooled	Application Usage
Amps	Duty Cycle	Gas			
200 Amps	60%	CO ₂ Carbon Dioxide	Up To .045" (1.2 mm)	Air	Medium Duty Fabrication

EASY FIND EASY FIND GUIDE
See Page 33 & 34 for Replacement Parts & Optional Accessories

Miller is a registered trademark of Illinois Tool Works, Inc. Lincoln is a registered trademark of Lincoln Electric Co. The aforementioned registered trademarks are in no way affiliated with Tweco. Tweco is registered trademark of ESAB.