



315C Pocket Digital Thermometer

Auto Field Calibrate to $\pm 2^{\circ}\text{F}$ in less than 10 seconds in ice water.

Features:

- Auto field calibration to $\pm 2^{\circ}\text{F}$
- Tapered stem (3.1 mm diameter) to fit into a Pete's Plug
- Reinforced, heavy-duty housing for strength
- Waterproof (IP63)
- Fits in your pocket
- -58°F to 300°F (-50°C to 150°C)
- Rugged design to withstand a 10 foot drop
- Magnetic clip perfect for air duct applications
- 3-year limited warranty


Applications:

HVACR

- Ambient Air
- Calibrate Thermostats
- Vents
- Compressor Heads
- Registers

ELECTRICAL

- Motor Temperatures
- Transformer Temperatures

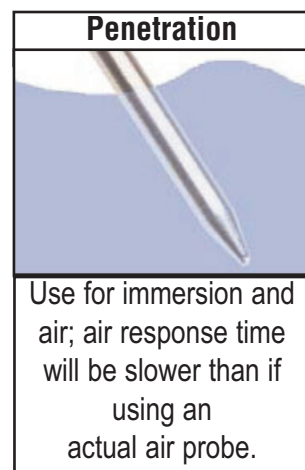

Pocket Digital Thermometer



Specifications:	
Temperature Range	-58°F to 300°F (-50°C to 150°C)
Accuracy	$\pm 2^{\circ}\text{F}$ ($\pm 1^{\circ}\text{C}$)
Resolution	$0.1^{\circ}\text{F}/^{\circ}\text{C}$
Sample Rate	1 reading every 1.5 second
Stem Length	2.8"
Tip Type	Penetration
Water Resistant	Yes
Water Proof	N/A
$^{\circ}\text{C}$ / $^{\circ}\text{F}$ Selectable	Yes
Data Hold	Yes
Auto Off	Yes
Battery Type	LR44