



MCR
SAFETY

9389PV
KS-4

**Cut Protection
Specification Sheet**

PRODUCT DESCRIPTION:

KS-4 combines DuPont™ Kevlar® and Stainless Steel construction to deliver CE cut level 5 protection. A textured HPT coating provides an enhanced grip and puncture protection. KS-4 provides higher levels of cut protection with enhanced grip in a lightweight, high dexterity shell for applications such as framing, glass & window installation, sharp part handling & assembly, sheet metal pressing and light stamping. Comes in vending packaging.

FEATURES:

- 13 Gauge Kevlar®/Stainless Steel/Nylon Shell
- Black Textured HPT Coating
- Offers enhanced grip
- Lightweight Hi-dexterity shell
- ANSI A4 Cut rating, gram weight 1925

APPLICATIONS:

Aerospace, Agriculture, Assembly Line Production, Bottling, Canning, Carpentry, Construction, Glass handling, HVAC, Landscaping, Material Handling, Metal fabrication, Millwright operations, Salvage, Stamping, Sheet metal industry



TECHNICAL DATA FOR: 9389PV

Series	KS-4
Material Group	Strings
Product Type	Cut Protection
Glove Size	Large
Gauge	13 Gauge
Material	Kevlar / Steel

EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	5
EN 388 : CE Score - Tear	4
EN 388 : CE Score - Puncture	3
ANSI Cut	ANSI Cut A4




MCR
SAFETY

9389PV

KS-4

Cut Protection Specification Sheet

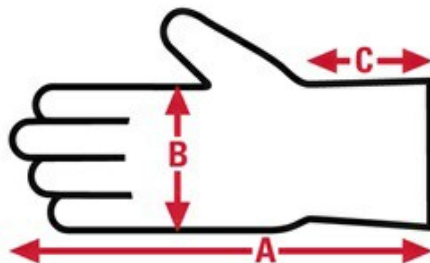

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9389PVL	Large	10.87	5.75	3.47	29.160 lb.	2.430
9389PVM	Medium	10.66	5.55	3.36	36.192 lb.	3.016
9389PVS	Small	10.12	5.21	3.32	34.260 lb.	2.855
9389PVXL	X - Large	11.54	6.00	3.52	44.256 lb.	3.688
9389PVXXL	XX - Large	12.20	6.20	3.60	52.480 lb.	4.373

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved