



MCR
SAFETY

9760R Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9760R Predator® features a premium rough nitrile palm and over the knuckle coating. The soft jersey liner is treated with Actifresh to reduce odors. The safety cuff adds additional protection.

FEATURES:

- Premium Rough Nitrile Coating
- Soft Jersey Lining
- Safety Cuff
- CE Score 4242
- Treated with Actifresh to reduce odor
- Component materials comply with all relevant federal regulations for food contact

APPLICATIONS:

Agriculture, Carpentry, Construction, Forestry, Landscaping,
Lumber industry, Manufacturing, Material Handling



TECHNICAL DATA FOR: 9760R

Series	Predator
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Nitrile
Grade	Premium
Lining	Jersey
Thumb Style	Straight

Overall Length	10 in.
EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	4
EN 388 : CE Score - Puncture	2




MCR
SAFETY

9760R

Predator

Supported / Dipped gloves
Specification Sheet

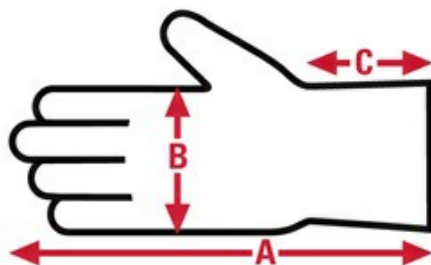

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9760R	Large	10.630	6.360	2.500	51.144 lb.	4.262

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved