



**MCR
SAFETY**

9761R Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9761 Predator® features fully coated rough premium nitrile on a soft jersey liner. Treated with Actifresh and has a 2.5" safety cuff.

FEATURES:

- Fully Coated Rough Premium Nitrile Coating
- Soft Jersey Lining
- CE Score 4224
- Component materials comply with all relevant federal regulations for food contact

APPLICATIONS:

Agriculture, Carpentry, Construction, Farming, Forestry, Landscaping, Lumber industry, Material Handling



TECHNICAL DATA FOR: 9761R

Series	Predator	Overall Length	11 in.
Material Group	Supported	EN 388 : CE Score - Abrasion	4
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Cut	2
Glove Size	Large	EN 388 : CE Score - Tear	2
Material	Nitrile	EN 388 : CE Score - Puncture	4
Grade	Premium	ANSI Cut	ANSI Cut A3
Lining	Jersey		
Thumb Style	Straight		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9761R Predator

Supported / Dipped gloves
Specification Sheet

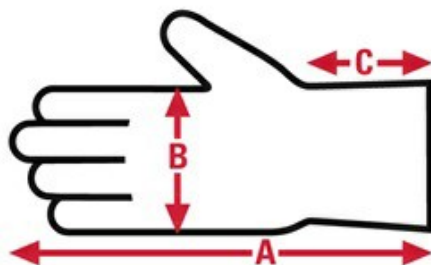

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9761R	Large	10.90	6.75	2.95	55.212 lb.	4.601
9761RM	Medium	10.236	5.984	2.500	51.216 lb.	4.268
9761RS	Small	10.160	5.700	2.500	45.948 lb.	3.829
9761RXL	X - Large	11.023	6.496	2.500	57.972 lb.	4.831

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved