



**MCR
SAFETY**

93891PU

UltraTech

Cut Protection Specification Sheet

PRODUCT DESCRIPTION:

Go Pro with Cut Pro gloves! The 93891PU combines DuPont™ Kevlar®, Synthetic Materials, and Stainless Steel construction to deliver outstanding cut protection! It also features a black polyurethane palm and fingers for additional grip and abrasion resistance.

FEATURES:

- DuPont™ Kevlar®, Synthetic Materials, and Stainless Steel material
- Black PU coated palm & fingers
- Superior Cut Protection with Enhanced Grip
- CE cut level 5, score = 4543
- ANSI Cut Level 4

APPLICATIONS:

Automotive Assembly, Bottling, Canning, Glass handling, HVAC, Sheet metal industry



TECHNICAL DATA FOR: 93891PU

Series	UltraTech
Material Group	Strings
Product Type	Cut Protection
Glove Size	Large
Gauge	10 Gauge
Material	Kevlar / Synthetic

EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	5
EN 388 : CE Score - Tear	4
EN 388 : CE Score - Puncture	3
ANSI Cut	ANSI Cut A4




MCR
SAFETY

93891PU

UltraTech

Cut Protection

Specification Sheet

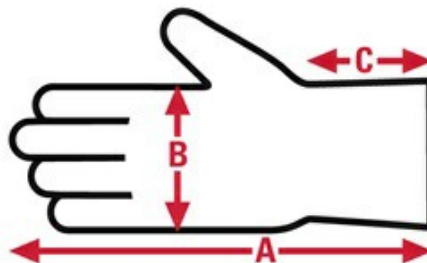

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
93891PUL	Large	9.85	5.56	3.35	29.580 lb.	2.465
93891PUM	Medium	9.45	5.28	3.35	26.856 lb.	2.238
93891PUS	Small	9.05	5.12	3.15	24.084 lb.	2.007
93891PUXL	X - Large	10.44	5.84	3.74	31.548 lb.	2.629
93891PUXXL	XX - Large	11.18	6.20	3.60	33.324 lb.	2.777

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved