



**MCR
SAFETY**

6712F

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

Frigid frozen fingers? No frickin' way, These foam-insulated gloves keep hands warm and dry. They are resistant to abrasions, oil, acids, chemicals and caustics.

FEATURES:

- Premium Foam Lined
- Orange Double Dipped PVC
- Fluorescent Orange
- Smooth Finish
- 12" Length

APPLICATIONS:

Cold storage applications, Fisheries, Transportation, Warehousing, Agriculture, Farming



TECHNICAL DATA FOR: 6712F


Material Group	Supported	Overall Length	12 in.
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Abrasion	3
Glove Size	Large	EN 388 : CE Score - Cut	1
Material	PVC	EN 388 : CE Score - Tear	2
Grade	Premium	EN 388 : CE Score - Puncture	1
Insulated	Insulated		
Lining	Foam		
Thumb Style	Wing		



MCR
SAFETY

6712F

Supported / Dipped gloves Specification Sheet

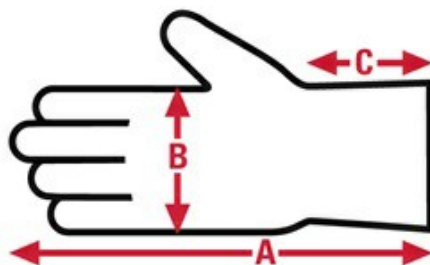

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6712F	Large	11.811	7.009	N/A	35.325 lb.	7.065

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved