



**MCR**  
**SAFETY**

# N9676DT

## Ninja

### Cut Protection Specification Sheet

#### **PRODUCT DESCRIPTION:**

DSM Dyneema® Diamond Technology takes gloves to a new level of protection by providing greater cut resistance with no compromise in comfort or durability. DSM Dyneema® Diamond Technology fiber is 40% lighter (less dense) than aramid fiber, enabling gloves that are both thinner and much lighter, while offering the same cut protection. The N9676DT features a 15 gauge DSM Dyneema Diamond Tech® and synthetic shell with a BNF (Breathable Nitrile Foam) coated palm and fingers. The BNF provides additional abrasion resistance and grip. The thumb crotch is reinforced with nitrile for added wear.

#### **FEATURES:**

- 15 gauge Gray DSM Dyneema Diamond Tech®, Nylon and fiberglass shell
- BNF coated palm and fingers
- Flat nitrile reinforced thumb crotch
- CE 4342 / ANSI Cut A3
- Touch screen friendly

#### **APPLICATIONS:**

Aircraft manufacturing, Assembly Line Production, Automotive Assembly, Carpentry, Construction, Glass handling, HVAC, Janitorial, Sheet metal industry, Roofing



#### **TECHNICAL DATA FOR: N9676DT**

|                       |                |
|-----------------------|----------------|
| <b>Series</b>         | Ninja          |
| <b>Material Group</b> | Supported      |
| <b>Product Type</b>   | Cut Protection |
| <b>Glove Size</b>     | Large          |
| <b>Gauge</b>          | 15 Gauge       |
| <b>Material</b>       | Dyneema        |

|                                     |                 |
|-------------------------------------|-----------------|
| <b>EN 388 : CE Score - Abrasion</b> | 4               |
| <b>EN 388 : CE Score - Cut</b>      | 3               |
| <b>EN 388 : CE Score - Tear</b>     | 4               |
| <b>EN 388 : CE Score - Puncture</b> | 2               |
| <b>ANSI Cut</b>                     | ANSI Cut A3     |
| <b>ANSI Puncture</b>                | ANSI Puncture 3 |

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2018 MCR Safety - All Rights Reserved




**MCR**  
**SAFETY**

# N9676DT

## Ninja

**Cut Protection**  
**Specification Sheet**

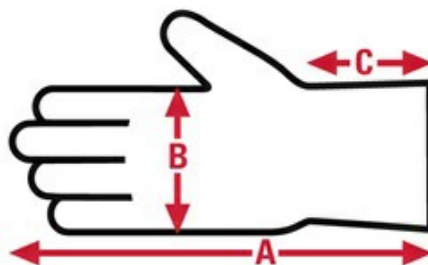

| Item No:   | Size:      | A: | B: | C:  | Case Weight | UOM Weight |
|------------|------------|----|----|-----|-------------|------------|
| N9676DTL   | Large      | 0  | 0  | N/A | 24.912 lb.  | 0.173      |
| N9676DTM   | Medium     | 0  | 0  | N/A | 23.184 lb.  | 0.161      |
| N9676DTS   | Small      | 0  | 0  | N/A | 20.592 lb.  | 0.143      |
| N9676DTXL  | X - Large  | 0  | 0  | N/A | 26.640 lb.  | 0.185      |
| N9676DTXXL | XX - Large | 0  | 0  | N/A | 28.224 lb.  | 0.196      |

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: [www.mcrcsafety.com](http://www.mcrcsafety.com)

©2018 MCR Safety - All Rights Reserved