


SNAPConnect® Tamper-Resistant Surge Protection Receptacle with Power Indicating LED




Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, surge suppression duplex receptacle, smooth face, 240 joules, 15kA peak current.	Blue	SNAP8262S	SNAP8362S
	Gray	SNAP8262GYS	SNAP8362GYS
	Ivory	SNAP8262IS	SNAP8362IS
	Light Almond	SNAP8262LAS	SNAP8362LAS
	Red	SNAP8262RS	SNAP8362RS
	White	SNAP8262WS	SNAP8362WS
Commercial Grade SNAPConnect® Tamper-Resistant, surge suppression duplex receptacle, smooth face, 240 joules, 15kA peak current.	Blue	SNAP5262S	SNAP5362S
	Gray	SNAP5262GYS	SNAP5362GYS
	Ivory	SNAP5262IS	SNAP5362IS
	Light Almond	SNAP5262LAS	SNAP5362LAS
	White	SNAP5262WS	SNAP5362WS

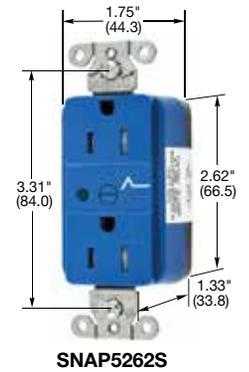

SNAP5262S

SNAPConnect® Tamper-Resistant Isolated Ground Receptacle


Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGTRA	SNAP8300IGTRA
	Red	SNAP8200RIGTRA	SNAP8300RIGTRA
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP2172IGTRA	SNAP2182IGTRA
	Red	SNAP2172RIGTRA	SNAP2182RIGTRA
Commercial Grade, isolated ground.	Orange	SNAP5262IGTRA	SNAP5362IGTRA
Style Line® decorator.	Orange	SNAP2152IGTRA	SNAP2162IGTRA

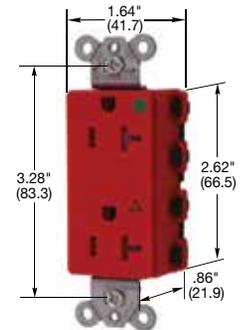

SNAP2182RIGTRA

SNAPConnect® Isolated Ground Receptacle with Power Indicating LED


Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGL	SNAP8300IGL
	Red	SNAP8200RIGL	SNAP8300RIGL
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP2172IGL	SNAP2182IGL
	Red	SNAP2172RIGL	SNAP2182RIGL
Commercial Grade, isolated ground.	Orange	SNAP5262IGL	SNAP5362IGL
Style Line® decorator.	Orange	SNAP2152IGL	SNAP2162IGL

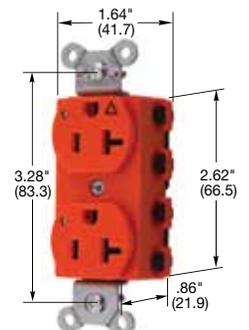

SNAP5362IGL

SNAPConnect® Tamper-Resistant Isolated Ground Receptacle with Power Indicating LED


Description	Color	Catalog Number	
Hospital Grade ● SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP8200IGLTRA	SNAP8300IGLTRA
	Red	SNAP8200RIGLTRA	SNAP8300RIGLTRA
Hospital Grade ● Style Line® decorator SNAPConnect® Tamper-Resistant, isolated ground, smooth face, duplex.	Orange	SNAP2172IGLTRA	SNAP2182IGLTRA
	Red	SNAP2172RIGLTRA	SNAP2182RIGLTRA
Commercial Grade, isolated ground.	Orange	SNAP5262IGLTRA	SNAP5362IGLTRA
Style Line® decorator.	Orange	SNAP2152IGLTRA	SNAP2162IGLTRA

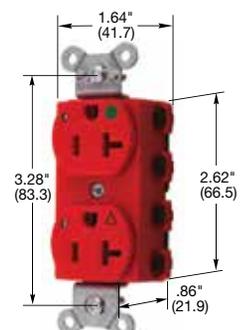

SNAP8300RIGLTRA

SNAPConnect® Right Angle Pigtailed Connector for General Use

Description	Solid Wire	Stranded Wire
Clear right angle terminal with 6 inch leads #12 AWG THHN/THWN-2, 600V, Polycarbonate housing material.	SNAP1RA	SNAP2RA

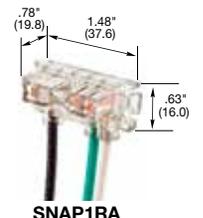

SNAP1RA

Note: See page Tech-10 for Tamper-Resistant and LED Power Indicators descriptions.

Dimensions in Inches (mm)