

Locking Devices



15 Amp Plugs, Connectors and Flanged Devices

15A 125V, 250V and 277V Locking Devices, 2-Pole 3-Wire Grounding Inches (mm)

TECH-SPEC®



Rating	Cord Diameter	Description	Nylon Plug Clamp-type Terminals		Nylon Connector Clamp-type Terminals		Flanged Devices Equipment Base with Nylon White Cup	
			Tripple Gripper	Regular	Tripple Gripper	Regular	Male	Female
NEMA L5-15, 15A 125V Plug Connector	.300"-.655" (7.6-16.6)	Black/White	4721NP	—	4732NC	4730	4716MB	4715ER
		All Black	4721NPB	4726BRY	4732NCB	—	—	—
		Corrosion-Resistant Yellow	4721NPCR	—	4732NCCR	—	—	—
		Angled 12-position Black/White	—	4722N	—	—	—	—
NEMA L6-15, 15A 250V Plug Connector	.300"-.655" (7.6-16.6)	Black/White	70615NP	—	70615NC	—	70615MB	70615ER
NEMA L7-15, 15A 277V AC Plug Connector	.300"-.655" (7.6-16.6)	Black/White	4770NP	—	4779NC	—	4786MB	4785ER


Weather Protective Boots

Description	For use with	Color	For Use with Plugs	For Use with Connectors
Thermoplastic elastomer boot	7465N plug when used with 7464N connector or 7468N female equipment receptacle, also for use with connector when used with 7466N male base	Black	7460BP	—
	7464N connector when used with 7465N plug	Black	—	7460BC
Neoprene boot	15 amp 2-pole 2-wire and midget locking nylon plugs and connectors, NEMA L1-15, ML-2 and ML-3	Yellow	7400BCR	7400BCR



Product Dimensions Inches (mm)

Triple Gripper Locking (B/W)		Locking (All Black)		Angled	Flanged Devices	
Plug	Connector	Plug	Connector	Plug	Male/Female	
A 2.18" (55.4)	2.95" (75.0)	2.00" (50.8)	2.78" (70.6)	2.07" (52.6)	A 2.50" (63.5)	
B 1.38" (35.1)	1.38" (35.1)	1.56" (39.6)	2.33" (59.2)	1.30" (33.0)	B 2.19" (55.6)	
C 1.53" (38.9)	1.53" (38.9)	1.53" (38.9)	1.53" (38.9)	1.52" (38.6)	C 2.00" (50.8)	
					D 1.84" (46.8)	
					E 1.68" (42.6)	
					F 1.58" (40.1)	

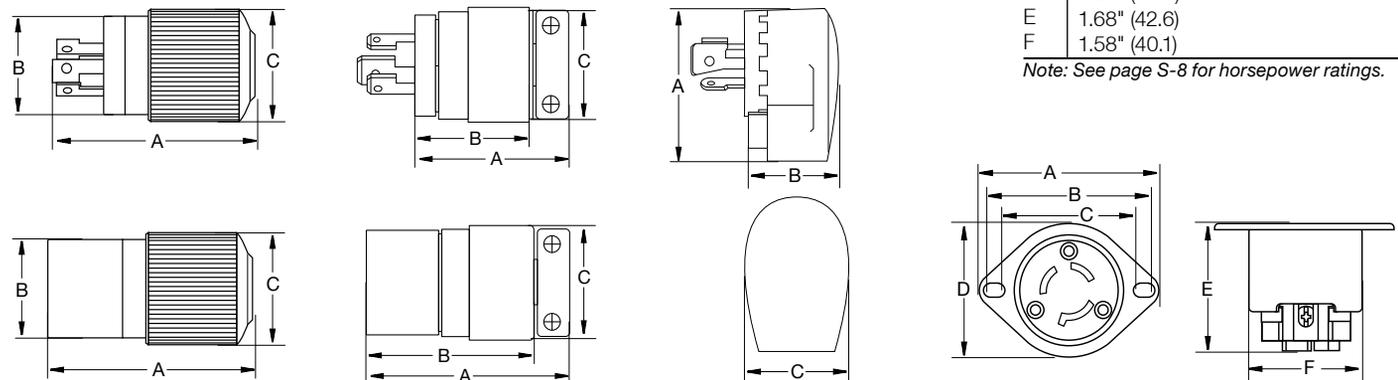

Note: See page S-8 for horsepower ratings.