



Cut



Medium Duty

Durable cut-resistant gloves offering advanced hand protection and dexterity

- **Advanced protection:** INTERCEPT™ Cut Resistance Technology helps HyFlex® 11-511 industrial gloves achieve ANSI A5/ISO E cut protection
- **Improved durability:** HyFlex® 11-511 industrial working gloves' nitrile foam coating ensures workplace safety for longer, with EN and ANSI level 4 abrasion resistance
- **Enhanced flexibility:** These HyFlex® gloves' special Cuff Over-Edging (ECO) yarn technology enables flexible wrist protection
- **Elevated comfort:** Their redesigned finger length also enhances comfort
- **Proven capabilities:** DuPont™ Kevlar® Stretch Armor liner offers them tried and tested dexterity in slightly oily or dry conditions
- **Reduced contaminants:** Latex- and silicone-free, these HyFlex® gloves are less irritable and prevent contaminant transfer to metal or paint



Industries

- Automotive
- Metal fabrication

Applications


- Press shop operations
- Handling metal sheets & panels
- Handling parts with sharp, rough edges
- Welding, bonding, riveting
- Handling structural and body components
- Inspection, selecting, checking parts
- Processing sheets, coils, tubes
- Cutting glasses, sheets, panels

Key Features

- **INTERCEPT[™] Cut Resistance:** Advanced ANSI A5/ISO E cut protection
- **Tough nitrile foam coating:** EN and ANSI level 4 abrasion resistance
- **Cuff Over-Edging (ECO):** PPE gloves with a flexible elastic cuff

Performance Standards & Regulatory Compliance

REACH Compliant

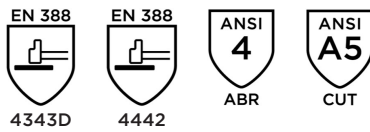

Technologies



Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	LENGTH	COLOR	PACKAGE
HyFlex [®] 11-511	Finishing: Palm Coated Coating Material: Foam Nitrile Liner Material: Kevlar [®] , Spandex, Stainless steel Cuff Style: Knitwrist	13	6, 7, 8, 9, 10, 11	225-282 mm; 8.86-11.10 inches	Green	• 12 Per Bag; 12 Bags Per Case

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
 Riverside Business Park
 Blvd International, 55
 1070 Brussels, Belgium
 T: +32 (0) 2 528 74 00
 F: +32 (0) 2 528 74 01

North America Region

Ansell Healthcare Products LLC
 111 Wood Avenue South,
 Suite 210
 Iselin, NJ 08830, USA
 T: +1 800 800 0444
 F: +1 800 800 0445

Australia

Ansell Limited
 Level 3, 678 Victoria Street,
 Richmond, Vic, 3121
 Australia
 T: +61 1800 337 041
 F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
 (Malaysia) Sdn Bhd
 Prima 6, Prima Avenue
 Block 3512, Jaijan Teknokrat 6
 T: +603 8310 6688
 F: +603 8310 6699

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
 Blvd. Bernardo Quintana No. 7001-C,
 Q7001 Torre II,
 Suites 1304, 1305 y 1306,
 Col. Centro Sur, c.p. 76079
 Queretaro, Qro. Mexico
 T: +52 442 248 1544 / 248 3133

Canada

Ansell Canada
 105 Lauder
 Cowansville, QC J2K 2K8
 Canada
 T: +1 800 363 8340
 F: +1 800 267 3551

Ansell, [®] and [™] are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.