




Item # M-51

Non-Sparking, Non-Magnetic, Corrosion-Resistant

Kit Includes:

- **Shoe Handle Brush:** B-399
- **Crate Opener, 9":** CJ-1-ST
- **Claw Hammer with Fiberglass Handle, 16oz.:** H-20FG
- **Common Knife, 5-3/4" Blade, 10-3/4" OAL:** K-5
- **Putty Knife (Stiff Blade), 1-1/4" X 3-9/16" Blade, 7-3/4" OAL:** K-21
- **Groove Joint Plier, 12":** P-312
- **Long-Nose Pliers with Cutters, 7":** P-326
- **Combination Pliers, 8":** P-31
- **Deck Scraper, 1-1/2" Blade, 15" OAL:** S-11G
- **Spray Booth Scraper, 3" Blade, 9-1/4" OAL:** S-40
- **Standard Screwdriver, 5/16" Tip, 6" Blade:** S-49
- **#3 Phillips Screwdriver:** S-1100
- **Tin Snips, 12":** S-1144
- **Adjustable End Wrench, 8":** W-71
- **Adjustable End Wrench, 12":** W-73
- **Adjustable Pipe Wrench, 14":** W-212AL
- **Bung Wrench, Fits 3/4" & 2" Bungs, 12":** W-56

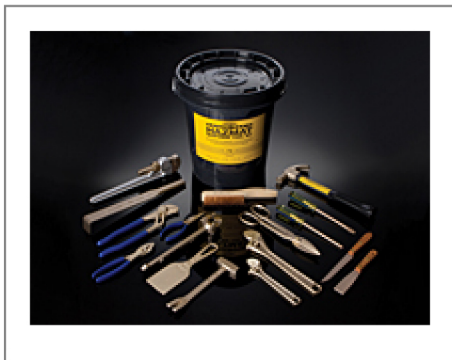

Specifications

-

length (mm)	345
width (mm)	345
height (mm)	415
Wt (g)	8915
length (in)	13-1/2
width (in)	13-1/2
height (in)	16-1/4
Wt (lbs)	19.65