

Designed for comfort, tactility and gripping delicate instruments

- Soft, elastic latex material provides exceptional comfort
- Thin, lightweight design for enhanced tactile sensitivity
- Textured fingers enable easier handling of small objects and delicate tools
- Complies with FDA food handling requirements
- Also available in vend pack (except EMEA)



Industries

- Life Sciences
- Food Processing
- Chemical

Recommended For

- Sample taking and processing
- Testing
- Vehicle maintenance
- Food contact
- All food processing, applications that have food contact
- Food processing and handling
- Meat, Fish and Food Processing
- Secondary food processing



TECHNICAL DATA SHEET

PRODUCT INFORMATION

| | |
|--|---|
| | 69-318 |
| Material | Natural Rubber Latex |
| Color | Natural |
| Glove Design | Chlorinated, Powder-Free, Silicone Free, Textured Fingers |
| Cuff | Beaded |
| Manufacturing/QMS Audit Standards | ISO 9001:2008 |
| Regulatory/Standards Compliance | Category III, EAC TP TC 019:2011, EN ISO 374-1:2016, EN 420:2003 + A1:2009, EN ISO 374-5:2016, EN 374:2003, FDA21 CFR 177-2600, ISO 9001, ISO 13485 |
| Packaging | 100 gloves per dispenser 10 dispensers per case 1000 gloves per case |
| Storage | Keep out of direct sunlight; store in a cool and dry place. Keep away from sources of ozone or ignition. |
| Country of Origin | Malaysia |
| User Needs Segment | Multi-Purpose |
| Available sizes | XS (5.5 - 6), S (6.5 - 7), M (7.5 - 8), L (8.5 - 9), XL (9.5 - 10) |
| Anti-static | Not Tested |

PHYSICAL PROPERTIES

| | Typical Values | | Testing Method |
|---|---------------------|--------------------|----------------------|
| Length (mm/inches) | 240 / 9.5 | | ASTM D3767, EN 420 |
| Freedom from Holes (Inspection level I) | 1.5 AQL | | ASTM D5151, EN 455-1 |
| Palm Thickness (mm/mils) | 0.12 / 4.7 | | ASTM D3767, EN 420 |
| Finger Thickness (mm/mils) | 0.14 / 5.5 | | ASTM D3767, EN 420 |
| | BEFORE AGING | AFTER AGING | |
| Ultimate Tensile Strength (MPa) | ≥ 18 | ≥ 14 | ASTM D412 & D573 |
| Elongation at Break (%) | ≥ 650 | ≥ 500 | ASTM D412 |

ORDERING INFORMATION

| Size | S (6.5 - 7) | M (7.5 - 8) | L (8.5 - 9) | XL (9.5 - 10) |
|---------------------|-------------|-------------|-------------|---------------|
| Product Code | 6931800S | 6931800M | 6931800L | 693180XL |

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
T: +603 8310 6688
F: +603 8310 6699

North America Region

Ansell Healthcare Products LLC
T: +1 800 800 0444
F: +1 800 800 0445

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
T: +52 442 248 1544 / 248 3133


Australia

Ansell Limited
T: +61 1800 337 041
F: +61 1800 803 578

Russia

Ansell PYC
Ten. +7 495 258 13 16

Performance Standards and Regulatory Compliance

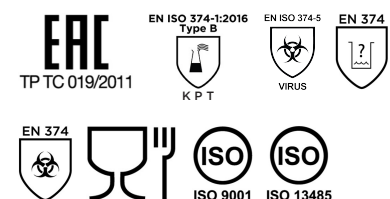

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending: www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.