



LED Party Bulbs

8A19/LED/YELLOW/P/ND 120V 4/1FB

Philips A shape party lamps provided a bright light and color to a wide variety of applications. Ideal for special occasions, parties, and holidays.


Product data

General Information	
Cap-Base	E26 [Single Contact Medium Screw]
EU RoHS compliant	Yes
Nominal Lifetime (Nom)	10950 h
Switching Cycle	20000X
Light Technical	
Beam Angle (Nom)	160 °
Correlated Color Temperature (Nom)	- K
Color Consistency	-
Color Rendering Index (Nom)	-
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Nom)	8 W
Lamp Current (Nom)	115 mA
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	80 °C

Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Shape	A19 (A19)
Approval and Application	
Energy Efficiency Label (EEL)	Not applicable
Energy Consumption kWh/1000 h	- kWh
Product Data	
Order product name	8A19/LED/YELLOW/P/ND 120V 4/1FB
EAN/UPC - Product	046677463250
Order code	929001998105
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001998105
Net Weight (Piece)	0.060 kg

LED Party Bulbs


Dimensional drawing

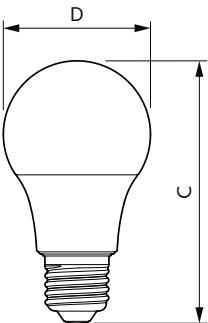


Bulb A19 8-W yellowlm yellowK E26 ND

Product	D	C
8A19/LED/YELLOW/P/ND 120V 4/1FB	60 mm	107 mm


Photometric data

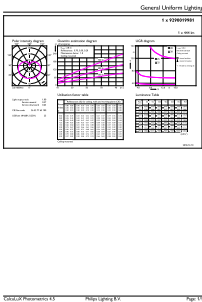

LEDbulb Color P 8W A19 E26 Yellow

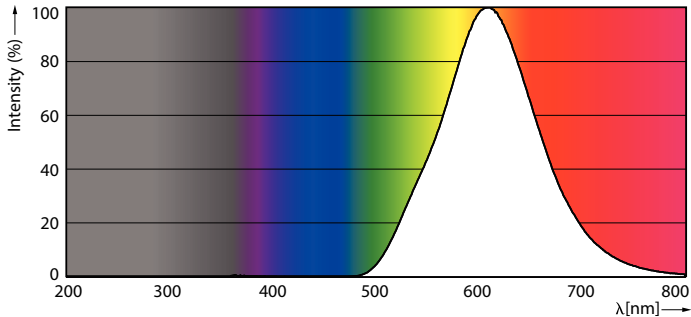



LEDbulb Color P 8W A19 E26 Yellow

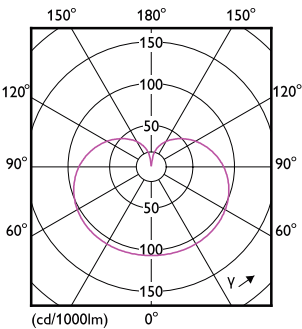

LEDbulb Color P A19 8W E26 Yellow

LED Party Bulbs

Lifetime

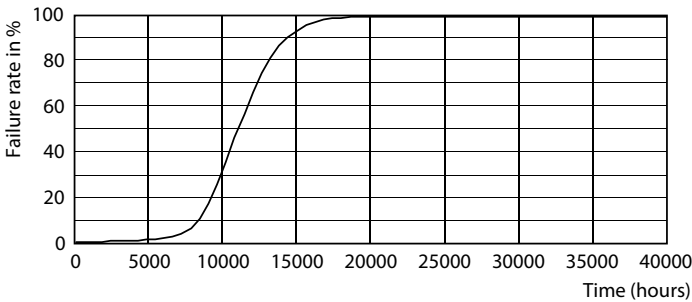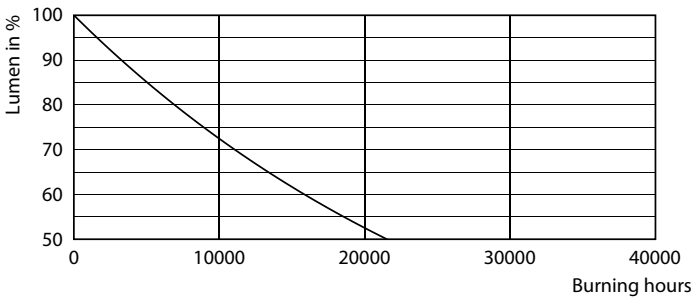

10K

10K

