



EcoTech[®]

**DIRECT DRIVE
BLOWER MOTOR**



Truck Stock



Universal Replacement



Ready to Install



Replaces Thousands
of OEM Motors

Improved
Reliability With:



Built-in 6,000 Volt
surge protection



Industry-leading
moisture protection



**PSC to
ECM
Upgrade**

SPECIFICATIONS

HORSEPOWER: 1/5, 1/4, 1/3, 1/2, 3/4 AND 1 HP

VOLTAGE: 1Ø, 115, 208-230 VAC

SPEEDS: 600 - 1075 RPM

ROTATION: REVERSIBLE

INPUTS: HIGH VOLTAGE TAP INPUTS

HERTZ: 50/60 HZ


OPERATION MODE: CONSTANT TORQUE

FRAME: NEMA®† 48

ENCLOSURE: OPEN AIR OVER (OAO)

EFFICIENCY: UP TO 82%

MOUNTING: BELLY-BAND

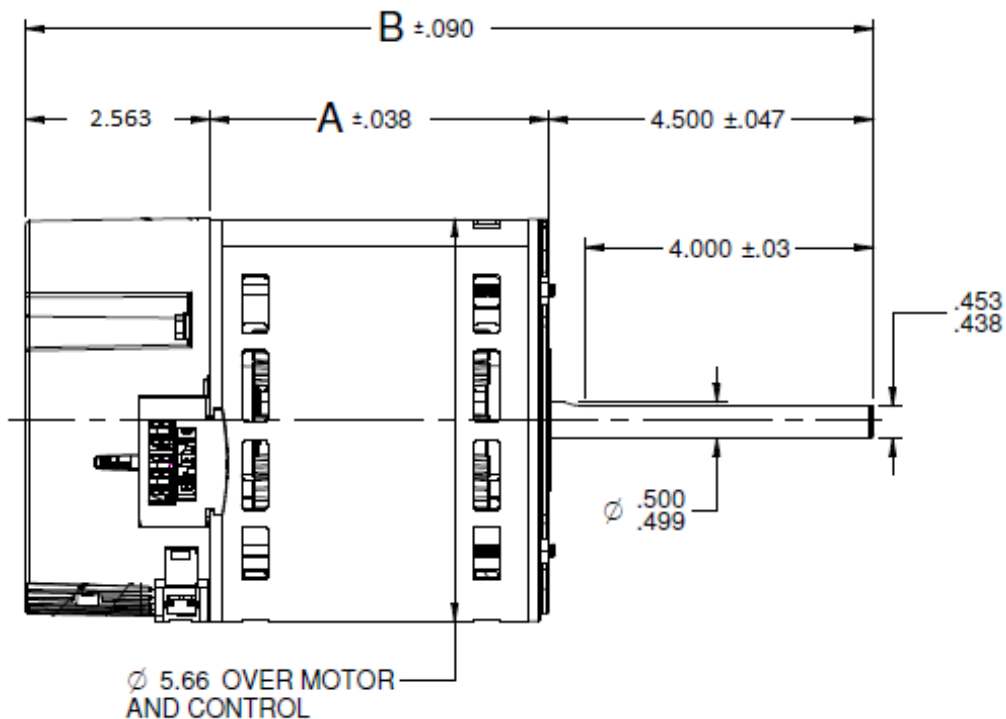

CATALOG NUMBER	HP	VOLTS	AMPS	RPM	DIM. A	DIM. B
5522ET	1/3-1/5	115/208-230	4.6/3.0-2.8	1075/Var	3.412	10.475
5532ET	1/2-1/4	115/208-230	6.8/4.4-4.1	1075/Var	3.662	10.725
5542ET	3/4-1/3	115/208-230	9.6/6.2-5.8	1075/Var	4.037	11.1
5552ET	1-1/2	115/208-230	12.6/8.1-7.4	1075/Var	4.412	11.475



8050 W. Florissant Avenue | St. Louis, MO 63136
Phone: 855-487-6686 | Fax: 800-899-2887

† All marks shown within this document are properties of their respective owners.

Nidec Motor Corporation, 2019; All Rights Reserved. U.S. MOTORS® is a registered trademark of Nidec Motor Corporation.
Nidec Motor Corporation trademarks followed by the ® symbol are registered with the U.S. Patent and Trademark Office.

19-8506-01 RESCUE ECOTECH PDS

