



Elastic cuff for a comfortable fit

Hi-vis color scheme

13-gauge acrylic and fiberglass blend shell with cut resistant fabric liner

Back-of-hand IR-X® Impact Exoskeleton™ with high-flex design provides ANSI/ISEA 138 Level 2 protection on knuckles and Level 1 protection on fingers

Launderable

Sandy nitrile palm coating provides superior grip and abrasion resistance


Fleece lining for warmth and insulation (interior layer)

High dexterity



2091 Thin Lizzie™ Thermal

PROTECTION ZONES:

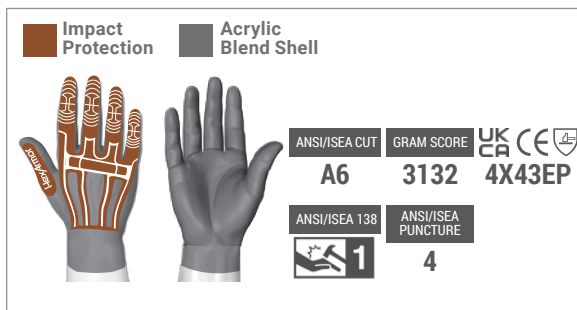

FEATURES:

The Rig Lizard® Series is purpose-built to provide maximum grip in tough situations – with over five grip options for water, oils, muds, and lubricants. Each glove is also equipped with our highly flexible IR-X® Impact Exoskeleton™, keeping hands protected from smash and pinch injuries. This combination of multiple technologies and features makes the Rig Lizard® the ideal solution for common oil, gas, and mining hazards. With options for cold weather protection, your hands can stay safe and comfortable in any environment.

ATTRIBUTES:

Style:	Seamless Coated
Grip:	Wet or dry
Cuff Style:	Elastic
Sizes:	6/XS through 11/XXL

HexArmor®

Call **1-877-MY ARMOR** or visit **hexarmor.com**

HexArmor® products are cut and puncture resistant, NOT CUT AND PUNCTURE PROOF. Do not use with moving or serrated blades or tools. User shall be exclusively responsible to assess the suitability of the product as specified for any individual application or use. Protection zones are to be used as a general guide. Actual product protection zones may differ. Product features, design, protection zones subject to change.

Protected by U.S. Patent No. D703,389