



## R-662

Leather comfort and dexterity with ideal impact and cut protection.



Impact

Abrasion Protection



Cut



Light Duty

## Premium leather cut resistant driver with impact protection and slip on cuff design for complete protection.

The Ringers 662 R-Hide Light Duty Impact glove is designed with high quality grain goatskin leather, providing protection against impact hazards and cuts in applications that require unsurpassed feel and dexterity.

- Developed with Ringers' F3 Technology™ and patented TPR design, using reinforced seams at the index and thumb to enhance durability and comfort.
- Includes cut resistant lining on palm, high visibility TPR, and slip-on elastic cuff for additional safety and ease-of-use.



### Industries

- Manufacturing
- Oil and gas
- Machinery and Equipment
- DIY
- Construction
- Automotive Aftermarket
- Metal fabrication

### Applications

- Preparation of site - unloading of lines and valves
- Handling iron - rigging work
- Handling of tools
- Heavy machine operation
- Equipment maintenance and repair
- Pipe handling
- Handling materials with sharp or rough edges
- Loading raw material



# R-662


Leather comfort and dexterity with ideal impact and cut protection.

## Key Features

- TPR impact protection on top of hand and full length of fingers
- Premium goatskin leather for comfort, dexterity and durability
- Palm lined with cut resistant material for cut protection
- Wrap-around index finger and thumb saddle patch to reinforce seams
- Wing-thumb construction and single full palm for flexibility
- Slip-on elastic cuff for easy on and off

## Performance Standards & Regulatory Compliance

### REACH Compliant

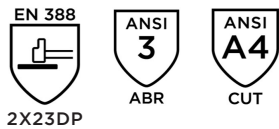

## Specifications

BRAND   STYLE	DESCRIPTION	Gauge	SIZE	COLOR	PACKAGE
RINGERS R662	<b>Liner Material:</b> Goatskin leather, HPPE <b>Cuff Style:</b> Slip-on		8, 9, 10, 11, 12	Hi Viz	• 5 pairs/bag, 10 bags/carton

For additional information visit us at [www.ansell.com](http://www.ansell.com), or call us at

#### Europe, Middle East & Africa Region

Ansell Healthcare Europe NV  
Riverside Business Park  
Blvd International, 55  
1070 Brussels, Belgium  
T: +32 (0) 2 528 74 00  
F: +32 (0) 2 528 74 01

#### Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.  
Blvd. Bernardo Quintana No. 7001-C,  
Q7001 Torre II,  
Suites 1304, 1305 y 1306,  
Col. Centro Sur, c.p. 76079  
Queretaro, Qro. Mexico  
T: +52 442 248 1544 / 248 3133

#### North America Region

Ansell Healthcare Products LLC  
111 Wood Avenue South,  
Suite 210  
Iselin, NJ 08830, USA  
T: +1 800 800 0444  
F: +1 800 800 0445

#### Canada

Ansell Canada  
105 Lauder  
Cowansville, QC J2K 2K8  
Canada  
T: +1 800 363 8340  
F: +1 800 267 3551

#### Australia

Ansell Limited  
Level 3, 678 Victoria Street,  
Richmond, Vic, 3121  
Australia  
T: +61 1800 337 041  
F: +61 1800 803 578

#### Asia Pacific Region

Ansell Global Trading Center  
(Malaysia) Sdn Bhd  
Prima 6, Prima Avenue  
Block 3512, Jalan Teknokrat 6  
T: +603 8310 6688  
F: +603 8310 6699

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:  
[www.ansell.com/patentmarking](http://www.ansell.com/patentmarking) © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

