

SUSPENSION SYSTEM MOLDINGS

LEED® WELL™ | LBC

UP TO **30% RECYCLED CONTENT**


energy management
 construction waste mgmt
 regional materials
 design for flexibility
 EPD
 recyclable/excise producer resp.
 biobased materials
 recycled content
 sourcing of raw materials
 material ingredient reporting
 low emitting materials
 lighting quality
 acoustics

Calculate sustainability with GreenGenie™
 armstrongceilings.com/greengenie

Angle molding, shadow molding, channel molding, and other wall moldings are an important detail in the design and installation of each ceiling system. Wall moldings offer a unique solution to each ceiling system by maintaining a consistent look and performance to each design.

LOCATION DEPENDENT


Shadow Molding:
 Hemmed with prefinished exposed flanges

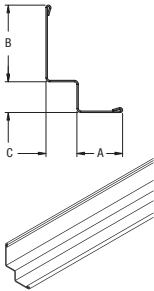

Item No.	Length	(A) Flange	(B) Height	(C) Reveal	LFT/Ctn.
7823*	120"	2"	1-1/4"	3/4"	100
7871	120"	3/4"	15/16"	3/4"	300
7873	120"	9/16"	15/16"	3/8"	300
7874	120"	9/16"	15/16"	1/4"	300
7875	120"	3/4"	15/16"	1/2"	300
7877*	120"	15/16"	15/16"	1/4"	300
7878*	120"	15/16"	15/16"	3/8"	300
7897*	120"	15/16"	15/16"	1/2"	300


* Suitable for IBC Category D, E, F installations.
 NOTE: Shadow molding can be rotated to be used with either flange.

Shadow molding:
 Hemmed with prefinished exposed flanges

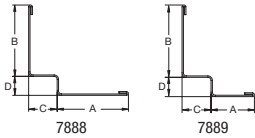

Item No.	Length	(A) Flange	(B) Height	(C) Reveal	(D) Reveal	LFT/Ctn.
7888	120"	15/16"	15/16"	3/8"	1/4"	300
7889	120"	9/16"	15/16"	3/8"	1/4"	300


 
Shadow Molding:
 (Compatible with Seismic Rx® and BERC 2)



Item No.	Length	(A) Flange	(B) Height	(C) Reveal	LFT/Ctn.
7877*	120"	15/16"	15/16"	1/4"	300
7878*	120"	15/16"	15/16"	3/8"	300
7897*	120"	15/16"	15/16"	1/2"	300

* Suitable for IBC Category D, E, F installations.
 NOTE: Shadow molding can be rotated to be used with either flange.


Shadow Molding:
 Inside and outside corners

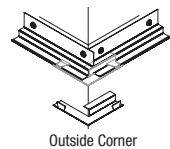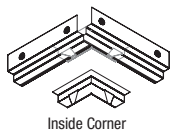


Item No.	Description
78741C	Inside Corner for 7874 Molding
78740C	Outside Corner for 7874 Molding
7861	Inside Corner for 7873 Molding
7862	Outside Corner for 7873 Molding
78771C	Inside Corner for 7877 Molding
78770C	Outside Corner for 7877 Molding
78781C	Inside Corner for 7878 Molding
78780C	Outside Corner for 7878 Molding

NOTE: Shadow molding can be rotated to be used with either flange (Corners will not work with rotated moldings).

Flex Molding:
 Steel base with flexible vinyl facing, minimum bending radius 6"

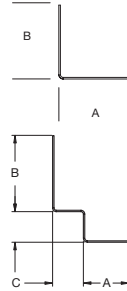


Item No.◆	Length	(A) Flange	(B) Height	(C) Reveal	LFT/Ctn.
Angle					
7880_*	96"	1"	1"	N/A	96
7882_*	96"	7/8"	15/16"	N/A	96
7884_*	96"	15/16"	15/16"	N/A	96
7885_*	96"	9/16"	1"	N/A	96
7887	96"	2"	1-1/2"	N/A	96
Shadow					
7890	96"	3/4"	1-5/8"	3/4"	96
7898	96"	9/16"	1"	3/8"	96

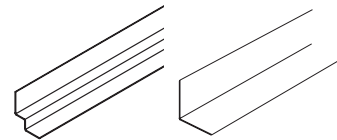


* Available in Black and White.

Channel Molding:
 Hemmed with prefinished exposed flanges

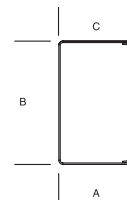

Item No.◆	Length	(A) Flange	(B) Height	(C) Reveal	LFT/Ctn.
7830	120"	15/16"	1-15/16"	15/16"	160
7831	120"	15/16"	1-9/16"	15/16"	200
7834	120"	15/16"	1-1/4"	1/2"	240
7835_*	120"	7/8"	1-3/4"	9/16"	200
7835SC**	11"	7/8"	1-3/4"	9/16"	150

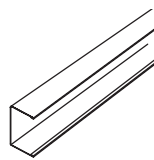

* Available in Gun Metal Grey and Silver Grey
 ** Unpainted spreader channel

Recommended moldings are included with suspension systems interface drawings on armstrongceilings.com/catdws

SUSPENSION SYSTEM MOLDINGS

LEED® WELL™ | LBC

UP TO **30% RECYCLED CONTENT**


Calculate sustainability with GreenGenie™ armstrongceilings.com/greengenie

- energy management
- construction waste mgmt
- regional materials
- design for flexibility
- EPD
- recyclable/extended producer resp.
- biobased materials
- recycled content
- sourcing of raw materials
- material ingredient reporting
- low emitting materials
- lighting quality
- acoustics

LOCATION DEPENDENT

Angle molding, shadow molding, channel molding, and other wall moldings are an important detail in the design and installation of each ceiling system. Wall moldings offer a unique solution to each ceiling system by maintaining a consistent look and performance to each design.


Angle Molding: Hemmed with prefinished exposed flanges

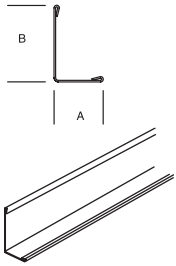


Item No. ♦	Length	(A) Flange	(B) Height	LFT/Ctn.
7800_*	144"	7/8"	7/8"	360
7800HRC	144"	7/8"	7/8"	360
7802	120"	7/8"	7/8"	300
7803_❖	144"	7/8"	7/8"	360
7804_**	144"	9/16"	7/8"	360
7804HRC	144"	9/16"	7/8"	360
780410	120"	9/16"	7/8"	300
7805	120"	1-1/2"	1-1/2"	300
7807_****	120"	2"	1"	100
7808_****	120"	2"	2"	100
780812	144"	2"	2"	120
7809	144"	15/16"	15/16"	360
7813	120"	3"	1"	200
7850	144"	1-1/8"	7/8"	360
7851	120"	1-1/8"	7/8"	300
HD7801_***	120"	7/8"	7/8"	300
HD7801G90	120"	7/8"	7/8"	300
SS7801	120"	7/8"	7/8"	300
AL7801	120"	7/8"	7/8"	300
SWA9854HRC	144"	1-1/4"	1-1/4"	144
SWA9878HRC	144"	7/8"	7/8"	144

- * Available in Tech Black, Light Grey, Grey Stone, Medium Taupe, Ivory, and White
- ** Available in Tech Black, Light Grey, Grey Stone, Medium Taupe, Ivory, White, Silver Grey, Silver Satin, and Gun Metal Grey
- *** Available in Silver Grey and Gun Metal Grey
- **** Available in Tech Black, White, Silver Grey, and Gun Metal Grey
- ❖ Pre-punched
- ♦ When specifying or ordering items with a color or finish, add the two-letter suffix to the end of the item number (e.g., 7807WH)


Slip-on Molding: For glue-up tile

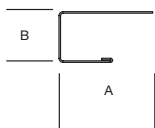


Item No.	Length	(A) Flange	(B) Height	LFT/Ctn.
7842	120"	1/2"	5/8"	400
7843	120"	1/2"	3/4"	400

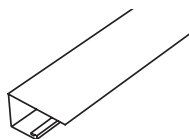

 
Fascia Molding: Prefinished exposed flanges




Item No.	Length	(A) Flange	(B) Height	LFT/Ctn.
7814	120"	1"	4"	50
7816	120"	1"	6"	50
7818	120"	1"	8"	50

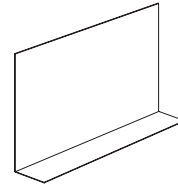


Reverse Angle Molding: Hemmed with prefinished exposed flanges

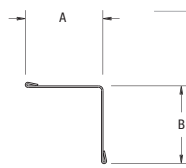


Item No.	Length	(A) Flange	(B) Height	LFT/Ctn.
7857	144"	15/16"	15/16"	360
7858	144"	1-9/16"	15/16"	240

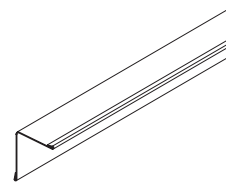

F Molding: For 1/2" and 5/8" drywall

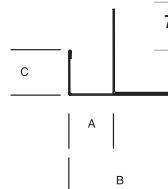

Item No.	Length	(A) Width	(B) Face	(C) Flange	LFT/Ctn.
7852	120"	1/2"	1-1/16"	7/8"	200
7856	120"	5/8"	1-3/16"	7/8"	200

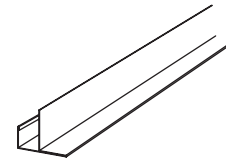

SUSPENSION SYSTEMS — Standard Moldings