

50A, 125V, 2 Pole, 3 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




50A 125V
NEMA 5-50R
UL CSA
2 HP



50A 125V
NEMA 5-50P
UL CSA
2 HP

Description	Cord Diameter	Catalog Number	
Receptacle, black RTP.	-	HBL9360	-
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	-	HBL9361

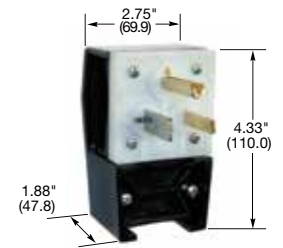

HBL9361

50A, 250V, 2 Pole, 3 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




50A 250V
NEMA 6-50R
UL CSA
3 HP



50A 250V
NEMA 6-50P
UL CSA
3 HP

Description	Cord Diameter	Catalog Number	
Receptacle, black RTP.	-	HBL9367	-
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	-	HBL9368

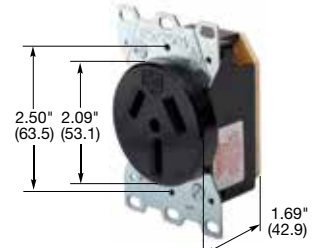

HBL9367

50A, 277V AC, 2 Pole, 3 Wire Grounding, Receptacles and Plugs

IP20
SUITABILITY




50A 277V AC
NEMA 7-50R
UL CSA
5 HP



50A 277V AC
NEMA 7-50P
UL CSA
5 HP

Description	Cord Diameter	Catalog Number	
Receptacle, black RTP.	-	HBL9365	-
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	-	HBL9379

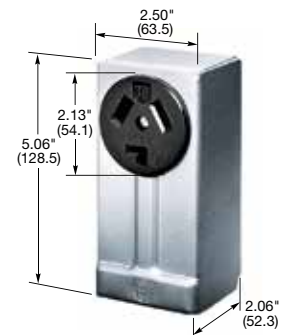

Representative of surface mount receptacle

50A, 125/250V, 3 Pole, 3 Wire Non-Grounding, Receptacles, Connector Body and Plugs

IP20
SUITABILITY




50A 125/250V
NEMA 10-50R
UL Listed
3(2) HP




50A 125/250V
NEMA 10-50P
UL Listed
3(2) HP

Description	Cord Diameter	Catalog Number	
Receptacle, black phenolic.	-	HBL7962	-
Receptacle, surface mount aluminum housing.	-	HBL7940	-
Connector body, Insulgrip, nylon.	.625"-1.218" (15.9-30.9)	HBL7515C	-
Plug, Insulgrip, nylon.	.625"-1.218" (15.9-30.9)	-	HBL7513C
Plug, nylon, angle, 4-position.	.625"-1.187" (15.9-30.2)	-	HBL7977

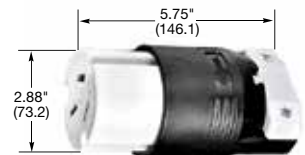

HBL7515C

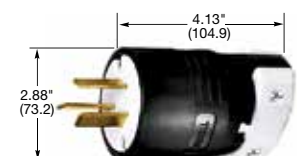

HBL7513C

Note: RTP is an abbreviation for reinforced thermoplastic polyester.
See pages A-49 and A-50 for accessories.

Dimensions in Inches (mm)