

Straight Blade Devices 50A, 3 Phase 250V AC, 3 Pole, 4 Wire Grounding Plug

HUBBELL

Features

- Gripping ribs provide secure gripping area
- Supertough nylon housing
- Catalog number, ratings and certifications molded in face

Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Plug, nylon	.625"-1.310" (15.9-33.3)	783585015163	HBL8451C



Listings

UL Listed File E1706
CSA Certified

Specifications

Housing	Supertough Nylon
Blade Holder	Reinforced Thermoplastic Polyester
Blades	Brass
Box Terminals	Copper Alloy
Mounting Screw	Stainless steel

Performance

Electrical


Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Product Identification	Ratings are a permanent part of the device
Terminal Accommodation	#12 AWG through #4 AWG copper wire only
Terminal Identification	Terminals identified in accordance with UL 498 and CSA

Environmental

Flammability	UL 94 HB
IP Suitability	IP20
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

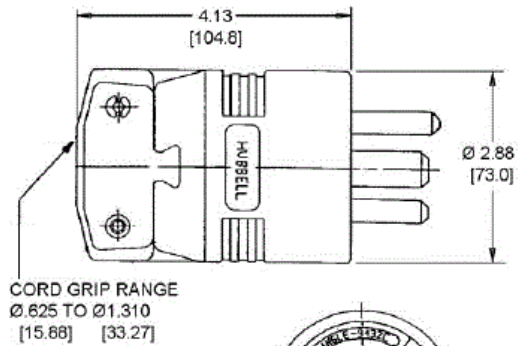

Resources

Customer Use Drawing
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

