



R-136

Tactile and secure cuff high visibility automotive glove.



Multi Purpose



Light Duty

Single layer hi-viz orange mesh with synthetic palm and touchscreen compatibility, when dexterity and flexibility matter most.

The Ringers 136 Turbo Plus glove provides flexible, lightweight protection with enhanced durability and touchscreen compatibilities for all-day automotive work.

- Developed with Ringers' F3 Technology™ for superior dexterity and comfort.
- Premium synthetic leather split-palm ensures excellent grip.
- High visibility orange, reflective markings, and hook and loop pull tab closure provides added security on the job.



Industries

- Automotive
- Automotive Aftermarket
- Food Processing
- Manufacturing
- Mining
- Oil and gas
- Machinery and Equipment

Applications

- General Purpose Auto Aftermarket
- Handling structural and body components
- Body painting including surface inspection
- Applying sealers, touching up
- Body panel repair and replacement
- Oil, fluids and filter change
- Engine transmission and repair
- Tire rotation & changes
- Storing and transportation
- Equipment maintenance and repair
- Driving fork lifts and vehicles
- Delivery of parts to production line
- Delivery of finished equipment
- Changing tools and dies
- Product inspection
- Vehicle Maintenance
- Re-fuel oil fluid and diesel
- Heavy machine operation
- Signalling/Positioning



R-136


Tactile and secure cuff high visibility automotive glove.

Key Features

- Secure cuff with hook and loop TPR pull tab closure
- Soft and durable premium mesh fabric on top of hand for optimal comfort and flexibility
- Premium synthetic leather used for split palm construction for long lasting durability
- Wrap around index finger protecting wear and tear zone
- Lightweight fabric between fingers for excellent dexterity
- Touchscreen compatible index, middle and thumb tips
- Reflective logo on top of hand for increased visibility

Performance Standards & Regulatory Compliance

REACH Compliant

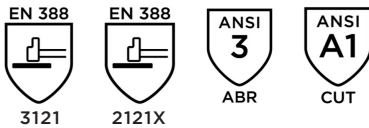

Specifications

BRAND STYLE	DESCRIPTION	Gauge	SIZE	COLOR	PACKAGE
RINGERS R136	Liner Material: N/A		7, 8, 9, 10, 11, 12, 13	Black and Red	• 5 pairs/bag, 24 bags/carton

For additional information visit us at www.ansell.com, or call us at

Europe, Middle East & Africa Region

Ansell Healthcare Europe NV
Riverside Business Park
Blvd International, 55
1070 Brussels, Belgium
T: +32 (0) 2 528 74 00
F: +32 (0) 2 528 74 01

Latin America & Caribbean Region

Ansell Commercial Mexico S.A. de C.V.
Blvd. Bernardo Quintana No. 7001-C,
Q7001 Torre II,
Suites 1304, 1305 y 1306.
Col. Centro Sur, c.p. 76079
Queretaro, Qro. Mexico
T: +52 442 248 1544 / 248 3133

North America Region

Ansell Healthcare Products LLC
111 Wood Avenue South,
Suite 210
Iselin, NJ 08830, USA
T: +1 800 800 0444
F: +1 800 800 0445

Canada

Ansell Canada
105 Lauder
Cowansville, QC J2K 2K8
Canada
T: +1 800 363 8340
F: +1 800 267 3551

Australia

Ansell Limited
Level 3, 678 Victoria Street,
Richmond, Vic, 3121
Australia
T: +61 1800 337 041
F: +61 1800 803 578

Asia Pacific Region

Ansell Global Trading Center
(Malaysia) Sdn Bhd
Prima 6, Prima Avenue
Block 3512, Jalan Teknokrat 6
T: +603 8310 6688
F: +603 8310 6699

Ansell, ® and ™ are trademarks owned by Ansell Limited or one of its affiliates. US Patented and US and non-US Patents Pending:
www.ansell.com/patentmarking © 2021 Ansell Limited. All Rights Reserved.

Neither this document nor any other statement made herein by or on behalf of Ansell should be construed as a warranty of merchantability or that any Ansell product is fit for a particular purpose. Ansell assumes no responsibility for the suitability or adequacy of an end user's selection of gloves for a specific application.

