

**30 Amp, 480 and 600 Volts AC
2 Pole, 3 Wire, Grounding**

IP20
SUITABILITY



30A 240V AC
NEMA L25-30P

30A 480V AC
NEMA L8-30P
5 HP

30A 600V AC
NEMA L9-30P

Plugs

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.325"-.930" (8.25-24)	HBL2601	HBL2641	HBL2651

Note: See page B-54 for accessories.




HBL2651

Flanged Inlets

Description	Catalog Number		
Nylon casing, back wired.	HBL2605	HBL2645	HBL2655

Note: See page B-54 for accessories.

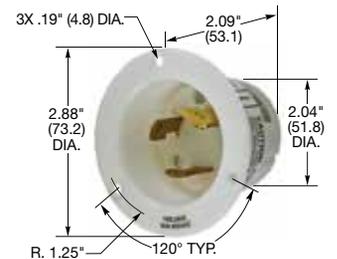

HBL2655

Connector Bodies

IP20
SUITABILITY



30A 240V AC
NEMA L25-30R

30A 480V AC
NEMA L8-30R
5 HP

30A 600V AC
NEMA L9-30R

Description	Cord Dia.	Catalog Number		
Black and white nylon.	.325"-.930" (8.25-24)	HBL2603	HBL2643	HBL2653

Note: See page B-54 for accessories.



HBL2653

Single Flush Receptacles

Description	Catalog Number		
Black nylon face, back and side wired.	HBL2600	HBL2640	HBL2650


Note: See page B-54 for accessories.

Flanged Receptacles

Description	Catalog Number		
Nylon casing, back wired.	-	HBL2646	HBL2656

Note: See page B-54 for accessories.

See page B-71 for technical information on Twist-Lock devices.

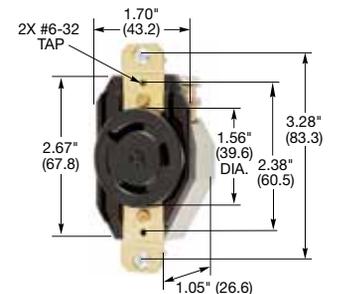

HBL2650



HBL2656

Dimensions in Inches (mm)