



MODEL L2 LEVER CONNECTORS L22, L23, & L25

FEATURES/BENEFITS:



- TRANSPARENT HOUSING ENABLES EASY VERIFICATION OF CONNECTION
- REDUCED LEVER ACTUATION FORCE COMPARED TO COMPETATIVE LEVER CONNECTORS
- 2-, 3-, AND 5- PORT CONFIGURATIONS ALLOW FOR WIDE VARIETY OF APPLICATIONS
- INDIVIDUAL LEVERS OPEN AND CLOSE EACH PORT INDIVIDUALLY
- LEVERS POSITIONED OPPOSITE OF WIRE PORT, REDUCING RISK OF INADVERTENT OPENING

ELECTRICAL:

VOLTAGE:
GENERAL: 600 V MAX
SIGNS/LUMINAIRES: 1,000 V MAX

MECHANICAL:

- Compact size to fit into confined junction boxes
- Wide levers ease actuation
- Profiled housing for improved grip
- Added latch feature to secure lever in closed position
- Solid wires may be inserted with opening lever

PHYSICAL:

HOUSING: PC (TRANSPARENT)
LEVERS: NYLON (BLUE)
TEMPERATURE: 105°C (221°F)
STRIP LENGTH (LOAD): 0.45in (12mm)
COLOR: TRANSPARENT/BLUE

STANDARDS & SPECIFICATIONS:


UL/cUL: 486C
UL/cUL: 467 GROUNDING
IEC/EN 60998
CE CERTIFIED
RoHS COMPLIANT
UL 94 V-2 FLAME RATING



WIRE RANGE:

	AWG	METRIC	STRIP LENGTH
SOLID	12-24AWG	0,2 - 4,0mm ²	0.45in [12mm]
STRANDED	12-24AWG	0,2 - 4,0mm ²	0.45in [12mm]

DIMENSIONS:

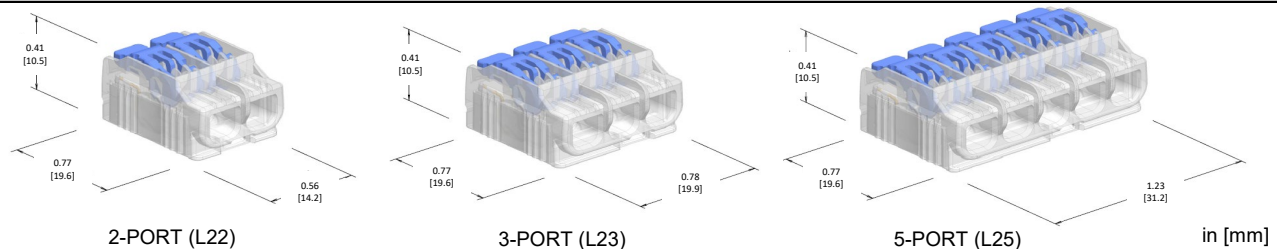

ORDERING INFO:

MODEL	PART #	PACKAGE TYPE
MODEL L22 2-PORT	30-10L22	150 BOX
	30-50L22J	500 JAR
	30-16L22	4,000 CARTON

MODEL	PART #	PACKAGE TYPE
MODEL L23 3-PORT	30-10L23	100 BOX
	30-35L23J	350 JAR
	30-16L23	2,500 CARTON

MODEL	PART #	PACKAGE TYPE
MODEL L25 5-PORT	30-10L25	75 BOX
	30-20L25J	200 JAR
	30-16L25	1,500 CARTON

FACTORY CONTACT:

IDEAL INDUSTRIES, INC.
1800 S. PRAIRIE DR. SYCAMORE IL
USA 60178
P: (800) 435-0705
F: (888) 222-6140
E: contactus@idealindustries.com

SALES CONTACT: