


SPEEDPOT KIT ASSEMBLY

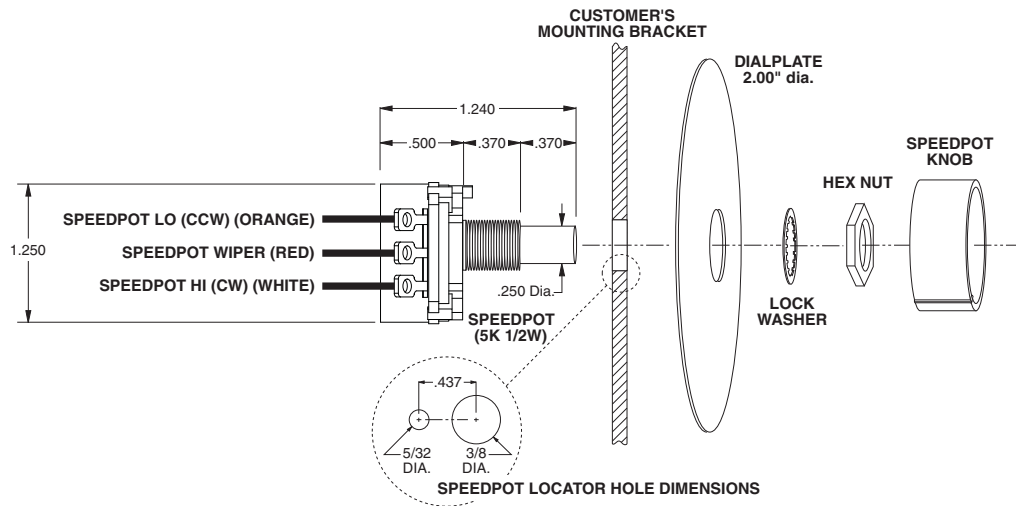

Dart Controls, Inc

PO Box 10
5000 W. 106th Street
Zionsville, Indiana 46077

Phone (317) 873-5211
Fax (317) 873-1105
www.dartcontrols.com

MORE DC MOTOR SPEED CONTROL PRODUCTS FOR YOUR EVERYDAY NEEDS



Stock # 5JJ58
1/40 - 2/3 Hp
NEMA 4 Enclosed



 
Stock # 2M510
1/50 Hp - 1.0 Hp
Open Chassis SCR



Stock # 6Z385A
1/50 Hp - 2.0 Hp
Open Chassis SCR



Stock # 5JJ62
Variable AC Voltage
control



Stock # 5HA33
1/15 - 1.0 Hp
Reversing Control



Stock # 6Z392
Shaft-mounted Hall-
Effect pulse generator



Stock # 6Z388B
1/4 - 2 Hp
NEMA 4/4X
Extra Features



Stock # 6Z386A
1/50 - 2 Hp
NEMA 4/4X
Extra Features



Stock # 1XC92A
Field Programmable
Closed-loop DC
Speed Control



Stock # 3VU55, 5JJ52, 6YC44
DC Input - Variable DC Output
10, 20, and 60 Amp Models



Stock # 3VU57
Field Programmable
Digital Tachometer
and Rate Meter

These and other controls available at W.W. Grainger, Inc.

SOPORTE DE MONTAJE DEL USUARIO

PLACA DE CUADRANTE DE 5,08 cm DE DIAMETRO

BOTON DE "SPEEDPOT"

ARANDELA DE CIERRA

TUERCA HEXAGONAL

SPEEDPOT LO (CCW) (NARANJA)

SPEEDPOT WIPER (ROJO)

SPEEDPOT HI (CW) (BLANCO)

SPEEDPOT (5K 1/2W)

3,17

1,27

0,94

0,94

0,6 DIA.

1,11

0,40 DIA.

0,95 DIA.

UBICACION Y DIMENSIONES DE LAS ABERTURAS DEL "SPEEDPOT"

SUPPORT DU FIXATION DU CLIENT

PLAQUE-CADRAN
5,72 cm DIA.

RONDELLE DE SECURITE

BOUTON DE POTENTIOMETRE

ECROU HEXAGONAL

POTENTIOMETRE (5K 1/2W)

ORANGE de SPEEDPOT LO (CCW)

ROUGE de SPEEDPOT WIPER

BLANC de SPEEDPOT HI (CW)

3,15

1,27

0,94

0,94

0,6 DIA.

3,17

1,11

0,40 DIA.

0,95 DIA.

DIMENSIONS DU TROU INDICATEUR DU POTENTIOMETRE