

DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP

DATA SHEET 6PY34, 6PY39



Technical Specs

6PY34


6PY39

SHIPPING WEIGHT	9.4 LBS	9.4 LBS
MAXIMUM LIQUID TEMPERATURE	180°F (82°C)	180°F (82°C)
INTAKE & DISCHARGE PORTS	1/2" SIDE-PORT NPT	1/2" SIDE-PORT NPT
FLOW	0 - 15 GPM MAX	0 - 15 GPM MAX
MAX AIR SUPPLY PRESSURE	100 PSI (1.4 - 7 KGF/CM ²)	100 PSI (1.4 - 7 KGF/CM ²)
BODY MATERIAL	POLYPROPYLENE	POLYPROPYLENE
LIFT-DRY, WET	8 FT, 28 FT	8 FT, 28 FT
AIR VALVE		
LUBRICATION	NO LUBRICATION REQUIRED	NO LUBRICATION REQUIRED
MANUAL OVERRIDE	YES	YES
LIQUID SIDE		
EASY REPAIR	YES	YES
FLAT CHECK VALVE	PTFE	PTFE
O-RINGS	EPDM	PTFE
DIAPHRAGMS	SANTOPRENE®	PTFE


DAYTON AIR-OPERATED DOUBLE DIAPHRAGM PUMP

6PY34, 6PY39

Dimensional Drawing

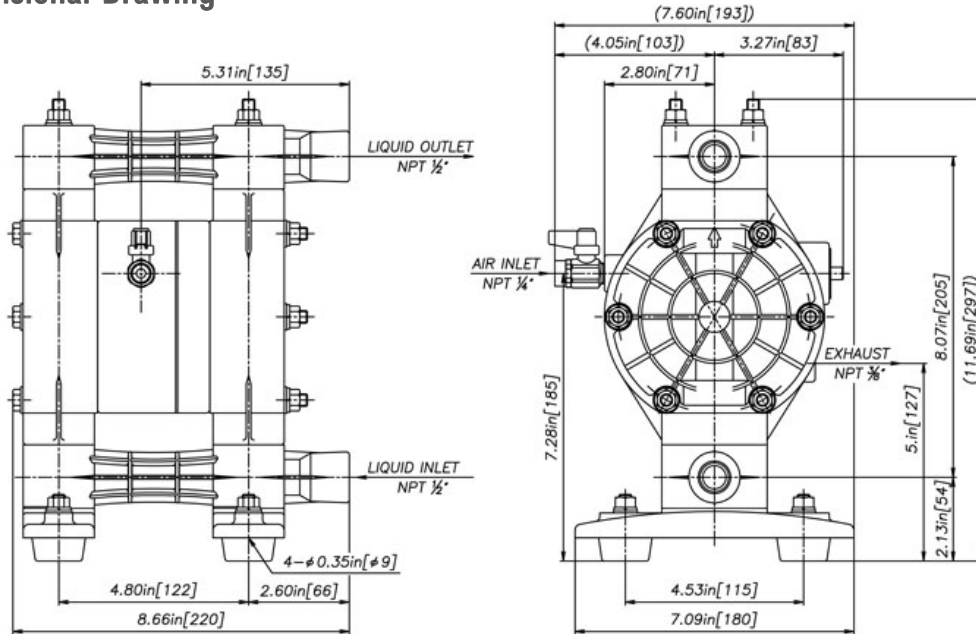

Performance Curve

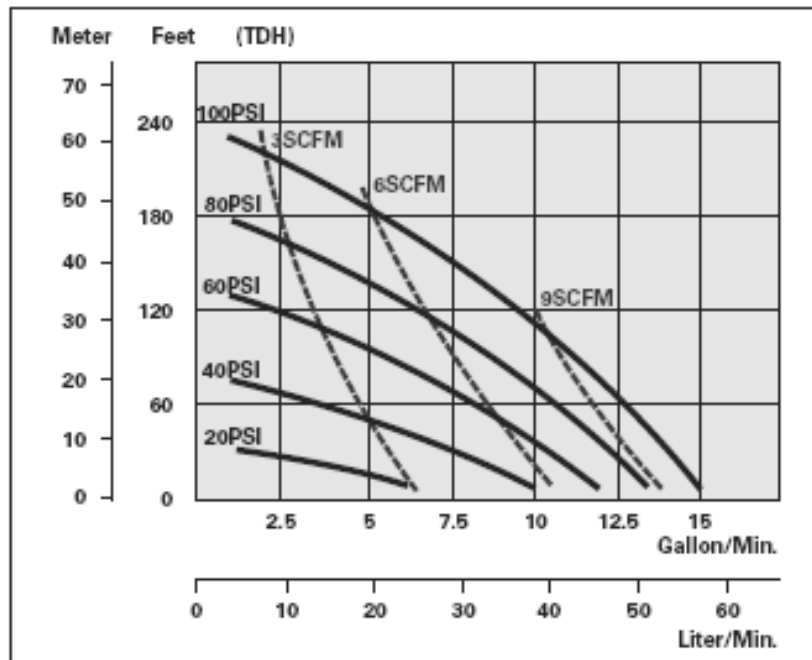

Find it at Grainger.

Call or visit your local branch or go to grainger.com/dayton for complete product line information.

