

Please read and save these instructions. Read through this owner's manual carefully before using product. Protect yourself and others by observing all safety information, warnings, and cautions. Failure to comply with instructions could result in personal injury and/or damage to product or property. Please retain instructions for future reference.



SIDE CABINET

Description

This Westward heavy-duty side cabinet has a durable coating and finish, sturdy construction, and heavy load capacity to extend product life. Heavy-duty full extension ball bearing slides ensure smooth functionality of all drawers. Each drawer can load up to 80 lbs(35kgs). Ball bearing slides have a quick release design that gives great flexibility when reconfiguring the drawers. The quick lock and auto return features of the cabinet are for added safety to prevent unwanted, accidental opening of drawers while in transit. The cabinet includes an internal locking system for added security. This cabinet is ideal for professional mechanics, and garage owners interested in storing and organizing tools and parts.



Unpacking

When unpacking unit, please ensure the unit is upright. Avoid using sharp objects to open the unit. After unpacking unit, inspect carefully for any damage that may have occurred during transit. Check for loose, missing, or damaged parts. Shipping damage claim must be filed with carrier.

Specifications and Dimensions

Model	Type	Description	No. of Drawers	Dimensions (Imperial/Metric)		
				Width	Depth	Height
32H864,32H865,32H866	Heavy Duty	SIDE CABINET	7	15.5"(394MM)	18.1"(460MM)	33.8"(858MM)
32H897,32H898,32H899	Heavy Duty	SIDE CABINET	5	15.5"(394MM)	18.1"(460MM)	33.8"(858MM)

General Safety Information

▲ CAUTION

Ensure the drawers are closed and locked completely before moving the cabinet.

Keep the product on level surfaces.

The product may become unstable and tip if stored or moved on an unlevel surface, which may cause personal injury or product damage.

▲ WARNING

Do not alter the product in any manner.

Do not step or climb on the cabinet.

Do not open more than one drawer at the same time.

Please make sure the cabinet is locked for transport.

Maintenance

Lubricate the lock with graphite annually. Lubricate the ball bearing slides with grease twice annually.





SIDE CABINET

Assembly

Refer to image below for mounting instruction.

1. After unpacking side cabinet ①, check carefully for any damage that may have occurred as hook of side cabinet ③.
2. Lift side cabinet ①, then mount trolley ②.

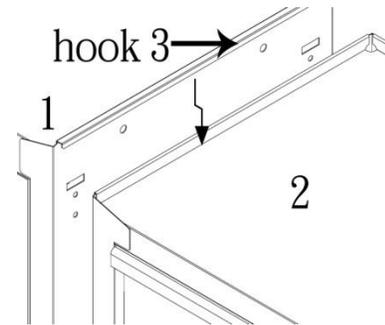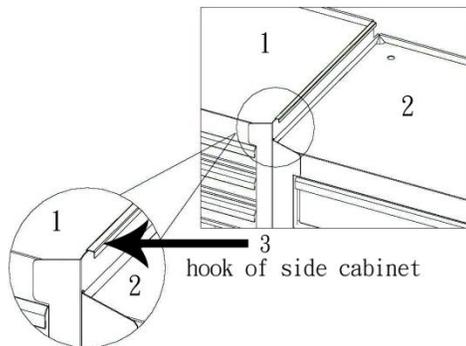

Warranty

LIMITED ONE-YEAR WARRANTY

Should this product fail to perform satisfactorily due to a defect or poor workmanship within ONE YEAR from the date of purchase, return it to the place of purchase and it will be replaced, free of charge. Incidental or consequential damages are excluded from this warranty.


Replace the lock parts

To release lock set:

1. Remove the spring clip ① using hand tool like pinchers.
2. Pull out the whole central lock including bolt ②, lock ③, central locking bar ④.
3. Separate the central locking bar ④ from lock ③, back hole ⑤.

To reinstall lock set:

1. Insert central locking bar ④ into back hole ⑤.
2. Assemble lock ③, central locking bar ④, bolt ② in sequence.
3. Insert spring clip ① on the lock.
4. Tighten the bolt ②.

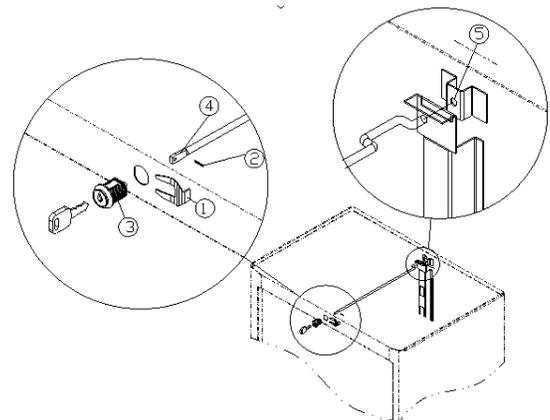




SIDE CABINET


To remove the drawer:

1. To remove the drawer, release the retaining clips by pushing the lever up on one side and down on the other side simultaneously.
2. Pull the drawer out.

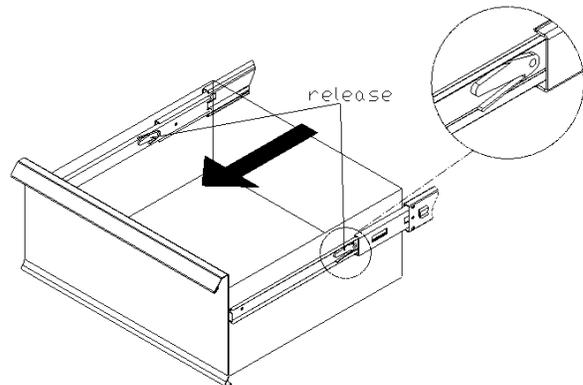

To install the drawer:

Place drawer on the slide rail and push into unit.
The user will not need to release or move the retaining clips.

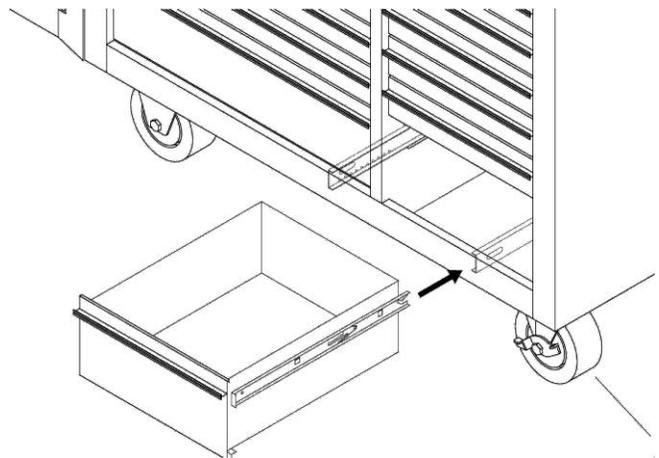

For Repair Parts, call 1-800-323-0620

24 hours a day – 365 days a year

Repair Parts List

Reference Number	Description	Part Number	Qty.
1	Key for 32H852-866. 32H885-899	MGC03XXX	1 pair
2	Lock set for 32H852-866. 32H885-899	TTLK003G	1 pc

(Please refer to the number on your key/lock for the last three digits.)