

GGT5® ARCTIC GATOR® 4031

Face the cold with confidence. The GGT5® Arctic Gator® 4031 combines the industry's highest levels of cut and impact protection with added layers of H2X™ and C40 Thinsulate™. Now your gloves can combat challenging conditions while your hands stay safe and warm.




the science of safety.®

HexArmor
ELITE WITH SuperFabric



GGT5® ARCTIC GATOR® 4031

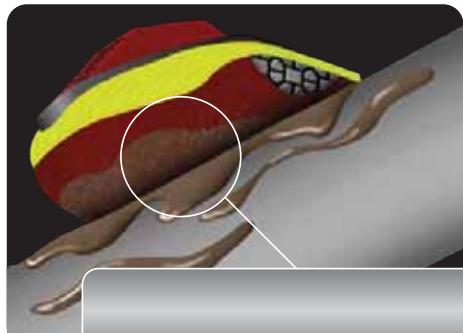

ARCTIC GATOR® 4031
TP-X® palm surface does not absorb fluids, allowing grip to be maintained in the presence of lubricating materials.



FEATURES:

- SuperFabric® brand material palm provides ISEA Level 5 cut resistance and maintains the highest level of protection available in the industry
- Dynamic combination of H2X™ and C40 Thinsulate™ interior liners for waterproof and cold resistance
- Puncture protection from wickers, burrs, and cable wire
- Full Impact Exoskeleton™ with high-performance IR-X® smash guards provides greater impact protection than the leading competitor
- Durable TP-X® palm utilizes the highest-level abrasion resistance while maintaining an oil-resistant grip
- Breathable SlipFit® cuff with pull tab and name tag
- Hi-vis color scheme increases visual awareness
- Launderable

Available in sizes 7/S through 12/3XL

ATTRIBUTES:



PROTECTION ZONES:



Call 1-877-MY ARMOR or visit hexarmor.com

HexArmor® products are cut and puncture resistant, NOT CUT AND PUNCTURE PROOF. Do not use with moving or serrated blades or tools. User shall be exclusively responsible to assess the suitability of the product as specified for any individual application or use. Protection zones are to be used as a general guide. Actual product protection zones may differ. Product features, design, protection zones subject to change. Protected by patents and patents pending.

HexArmor®
ELITE 