





Reach Farther Clean Smarter

Efficient air gun for cleaning hard-to-reach areas.

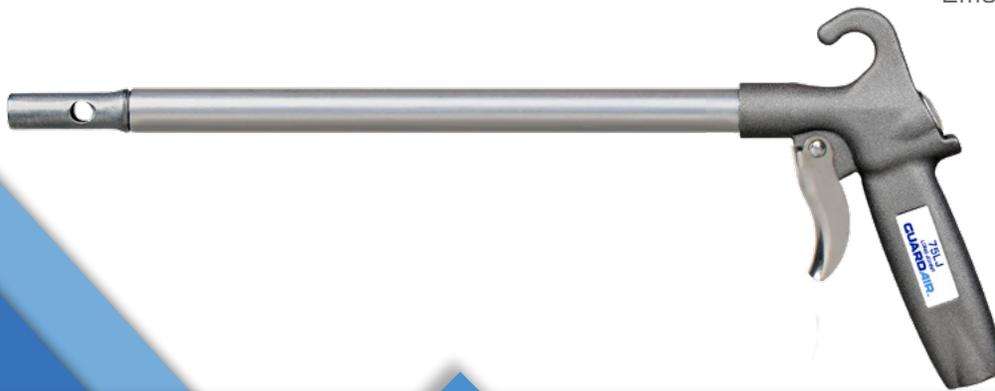

OSHA Safety Air Guns

All Guardair Safety Air Guns are designed with nozzles that meet or exceed OSHA STANDARD 1910.242(b) 30 psi requirement.

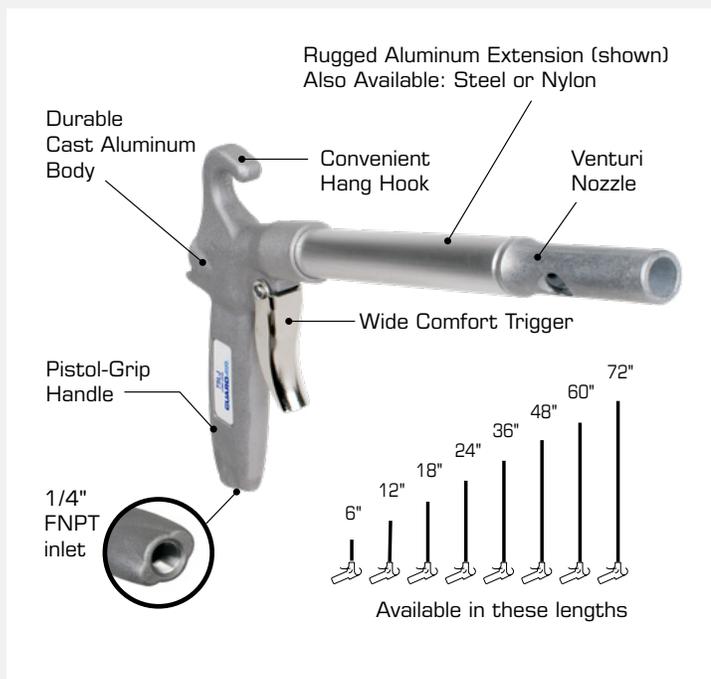

Long John®

The perfect tool for cleaning inaccessible and hard-to-reach areas, Long John® safety air guns are used for blowing floor debris, cleaning masonry forms, tanks, ovens, molds, and rafters, as well as machinery and storage areas. Efficient venturi nozzle boosts thrust up to 200% over conventional air guns, yet limits static pressure to less than 30 psi should the tip become blocked. Ergonomic, Classic+ pistol grip-style handle provides maximum user comfort.

- 34 CFM Compressed Air Usage
- 7.6 HP Minimum Compressor Size
- 107 dBA Noise Level



ALUMINUM

Part Number	Extension Length
75LJ006AA	6"
75LJ012AA*	12"
75LJ018AA	18"
75LJ024AA*	24"
75LJ036AA*	36"
75LJ048AA	48"
75LJ060AA	60"
75LJ072AA	72"

Lightweight to reduce operator fatigue during extended cleaning. *Available in 10 packs.



STEEL

Part Number	Extension Length
75LJ012SS	12"
75LJ024SS	24"
75LJ036SS	36"
75LJ048SS	48"
75LJ060SS	60"

Heavier and more rugged than aluminum. Built for maximum durability in tough environments.



NYLON

Part Number	Extension Length
75LJ012NN	12"
75LJ024NN	24"
75LJ036NN	36"

Insulated nylon extension and nylon nozzle protects users from electrical shock hazards and protects equipment from damage due to accidental short circuits.

FREE OSHA KIT

Test your air guns for safety.



Stay OSHA compliant and keep your team safe with our Free OSHA Compliance Kit. Test your pneumatic air guns, meet regulations, and enhance workplace safety. Order yours today!



FREE OSHA KIT