


# PIG® Absorbent Mat Roll

#MAT153 - Medium-weight • 30" x 150'

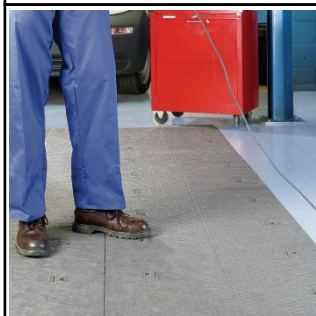

PIG Mat lasts 2x longer than ordinary mats for fewer change-outs. Absorbs everything. Works everywhere.

- Lasts 2X longer than ordinary mats for fewer change-outs, absorbs everything, works everywhere; that's why more plants worldwide use PIG Mat than any other brand
- Eight layers of 100% polypropylene are thermally bonded to make PIG Mat the strongest mat on the market; won't rip, tear or fray even when saturated
- Exclusive dimple pattern speeds wicking of liquid throughout mat for faster, easier cleanup
- Highly absorbent, fine-fiber construction won't leave liquids or fiber residue behind
- Absorbs most common industrial liquids - oils, water, solvents, coolants and more
- Absorbed leaks and drips blend right in; dark gray color hides grime so mat stays on the job longer
- Flame-resistant material won't burn immediately like cellulose mats; melts when exposed to high heat while on the job
- Can be wrung out and incinerated after use to reduce waste or for fuels blending
- Rolls are ideal for covering large areas and soaking up leaks and overspray
- Easy-tear perforations let you take only what you need, so you use less mat and save money
- Medium-weight construction offers great performance for everyday tasks and cleanups

Always in stock. Ships within 24 hours.



**New Pig**

By Phone:  
**1-855-493-HOGS**

Online:  
**[newpig.com](http://newpig.com)**

Email:  
**[hothogs@newpig.com](mailto:hothogs@newpig.com)**

One Pork Avenue • Tipton PA 16684-0304

© 2014 New Pig Corporation. All rights reserved.  
PIG and the PIG logo are trademarks in the U.S. and other countries.

ITEM: MAT153 - Pg 1 of 2

## MAT153 Specifications

<b>Color:</b>	Gray
<b>Dimensions:</b>	30" W x 150' L
<b>Mat Weight:</b>	Medium-weight
<b>Fluids Absorbed:</b>	Oils, Coolants, Solvents & Water
<b>Recycled Content:</b>	50% Recycled Content
<b>Absorbency:</b>	Up to 31.9 gal. per bag
<b>Absorbency per:</b>	Up to 31.9 gal. per roll
<b>Dispenser:</b>	No
<b>Perforated:</b>	Every 10" Lengthwise & Centered Widthwise
<b>Poly-Backing:</b>	No
<b>UV Resistant:</b>	No
<b>Sold as:</b>	1 roll per bag
<b>Weight:</b>	24.16 lbs.
<b># per Pallet:</b>	16
<b>Composition:</b>	100% Polypropylene
<b>UNSPSC:</b>	47131901

## Technical Information

### Warnings & Restrictions:

There are no known warnings and restrictions for this product.

### Regulations and Compliance:

29 CFR 1910.22(a)(2) - Floors in the workplace should be, "maintained in a clean and, so far as possible, a dry condition."

### Technical Documents:

(Available at [newpig.com](http://newpig.com))

Product Data Sheet (PDS)

Safety Data Sheet (SDS)

Chemical Compatibility (CCG)



## MAT153 Metric Equivalent

<b>Dimensions:</b>	76.2cm W x 46m L
<b>Absorbency:</b>	Up to 120.7 L per bag
<b>Absorbency per:</b>	Up to 120.7 L per roll
<b>Weight:</b>	11 kg



**New Pig**

By Phone:  
**1-855-493-HOGS**

Online:  
**[newpig.com](http://newpig.com)**

Email:  
**[hothogs@newpig.com](mailto:hothogs@newpig.com)**

One Pork Avenue • Tipton PA 16684-0304

© 2014 New Pig Corporation. All rights reserved.  
PIG and the PIG logo are trademarks in the U.S. and other countries.

ITEM: MAT153 - Pg 2 of 2