


Standard features

- Waterproof
- Impact resistant
- Conditional lifetime guarantee
- Crushproof
- Dustproof
- Powerclaw™ latching system
- Soft grip foldable handle
- Lightweight NK-7™ resin
- Padlockable
- 100% stainless steel hardware
- High performance gasket
- Automatic pressure release valve
- Molded-in bezel system
- Integrated lid stay
- Stackable
- Meets airline carry-on regulations

Case specifications

Exterior dimensions	L12.5" x W10.1" x H6.0" L318mm x W257mm x H152mm
Interior dimensions	L9.4" x W7.4" x H5.5" L239mm x W188mm x H140mm
Weight (empty)	3.3 lbs 1.5 kg
Lid depth	1.4" 36mm
Base depth	4.1" 104mm
Material	lightweight NK-7™ resin
Max buoyancy	17 lbs 7.7 kg
Temperature range	Min -20°F (-29°C) Max 140°F (60°C)
Airline carry-on	yes
Watertight	yes
Warranty	conditional lifetime guarantee

Available options

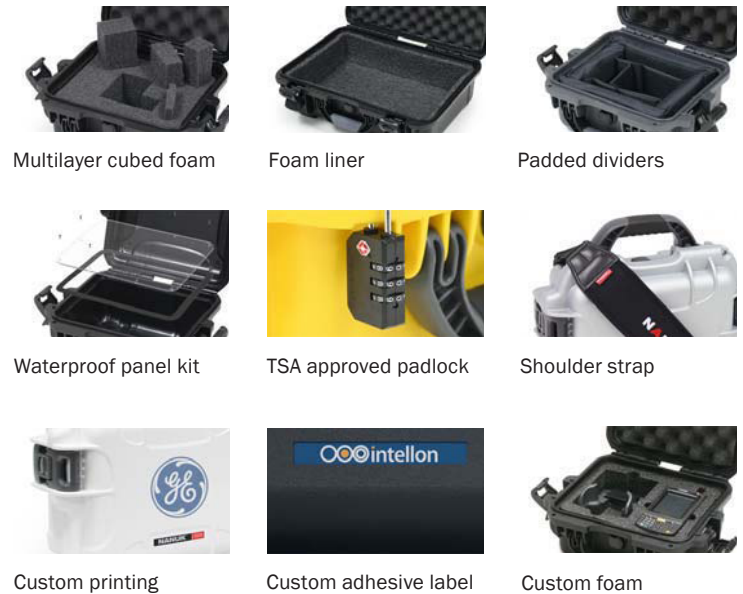

Certifications

ATA 300	Impact test
ASTM D4169	Falling rain - Vibration - Drop tests
Mil-STD-810F	Immersion test
IP 67	Ingress protection tests (dust & immersion)

Packaging specifications

Quantity per pack	1
Pack dimensions	L12.7" x W10.3" x H6.2" L320mm x W260mm x H155mm
Pack weight (no foam)	4.2 lbs 1.9 kg

Available colors



Masterpack specifications

Items per masterpack	6
Masterpack dimensions	L19.5" x W14.4" x H21.75" L495mm x W365mm x H550mm
Masterpack weight	26.9 lbs 12.2kg