




Standard features

- Waterproof
- Impact resistant
- Conditional lifetime guarantee
- Crushproof
- Dustproof
- PowerclawTM latching system
- Soft grip foldable handle
- Lightweight NK-7TM resin
- Padlockable
- 100% stainless steel hardware
- High performance gasket
- Automatic pressure release valve
- Molded-in bezel system
- Integrated lid stay
- Stackable

Case specifications

Exterior dimensions	L25.1" x W19.9" x H8.8" L638mm x W505mm x H224mm
Interior dimensions	L22.0" x W17.0" x H8.2" L559mm x W432mm x H208mm
Weight (empty)	10.6 lbs 4.8 kg
Lid depth	2.1" 53mm
Base depth	6.1" 155mm
Material	lightweight NK-7 TM resin
Max buoyancy	120 lbs 54.4 kg
Temperature range	Min -20°F (-29°C) Max 140°F (60°C)
Airline carry-on	no
Watertight	yes
Warranty	conditional lifetime guarantee

Available options

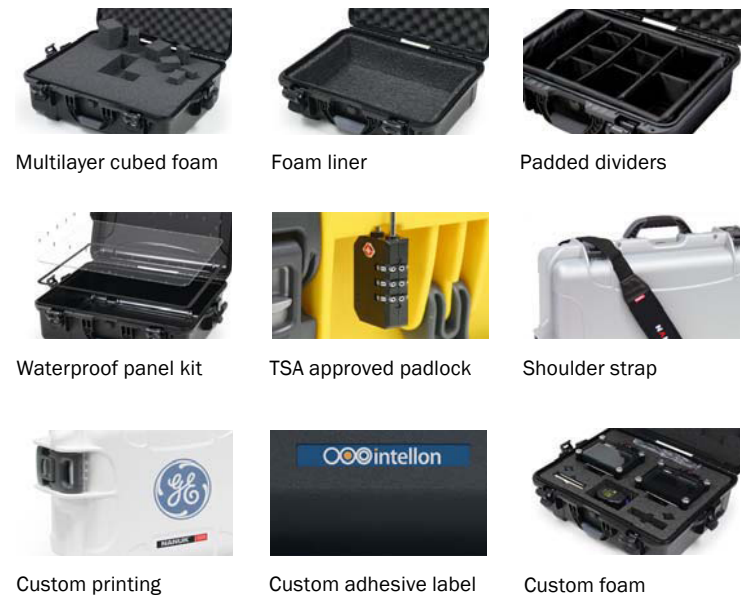

Certifications

ATA 300	Impact test
ASTM D4169	Falling rain - Vibration - Drop tests
Mil-STD-810F	Immersion test
IP 67	Ingress protection tests (dust & immersion)

Packaging specifications

Quantity per pack	1
Pack dimensions	L25.0" x W9.1" x H20.1" L635mm x W231mm x H511mm
Pack weight (no foam)	12.8 lbs 5.8 kg

Available colors

