



PODIUM[®] WITH CASTERS

300lbs TYPE IA

Load Capacity

Duty Rating



WORK FACING ANY DIRECTION



Factory installed casters for added mobility



Extra-large Platform



36" high extended guard rail



LOCKTOP™ secures tools and accessories




PODIUM[®] WITH CASTERS

ADDED MOBILITY FOR WORKING AT FIXED HEIGHTS



Waist-High Guard Rail

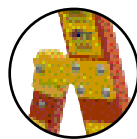

Solid Rivet Construction



Full Set of Rear Horizontals



Seven-Layer Fiberglass Construction




Customize your Ladder Top with Multiple Accessories



Podium Platform with Toe Guard



Full Aluminum Bracing

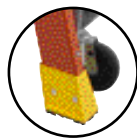

Model PD6204-4C

Factory-Installed Casters

The NEW PD6200-4C Podium Ladder series with factory installed casters for added mobility is ideal for working at fixed heights and is easier to maneuver than scaffolds or lifts.

- The extra-large platform with toe guard feels like you are standing on the ground.
- This ladder features full aluminum bracing and a full set of rear horizontals.
- LOCKTOP™ extended guardrail provides an extra point of contact and conveniently organizes tools and accessories.
- The durable caster assembly with stainless steel spring, steel stem and ball bearing swivel eliminates the need for a separate brake.
- The 4 soft rubber casters allow for easy 360 degree mobility and designed to roll over thresholds.

SPECIFICATIONS

★★★★ **300** lbs. LOAD CAPACITY Includes User and Materials Type IA Duty Rating

Model No.	Platform Height	Maximum Reach	Comparable Stepladder Height	Approx. Weight
PD6203-4C	3'	9'	5'	21 lbs.
PD6204-4C	4'	10'	6'	26.5 lbs.
PD6206-4C	6'	12'	8'	38.5 lbs.
PD6208-4C	8'	14'	10'	45.5 lbs.
PD6210-4C	10'	16'	12'	57.0 lbs

LOCK-IN ACCESSORIES



AC27-P Lock-In Paint Cup



AC50-JB-3 Lock-In Job Bucket



AC52-UB Lock-In Utility Bucket



AC54-JC Lock-In Job Caddy

wernerpodium.com

WERNER CO. CORPORATE HEADQUARTERS: 93 Werner Rd., Greenville, PA 16125-9499
TEL: 888-523-3370 FAX: 724-588-0315 www.wernerladder.com