
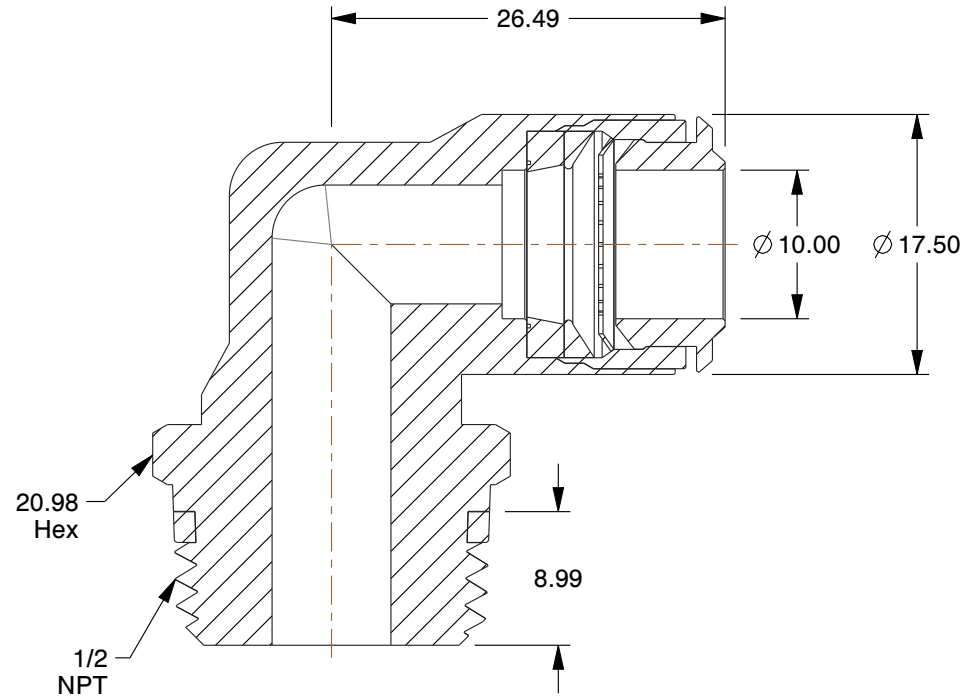
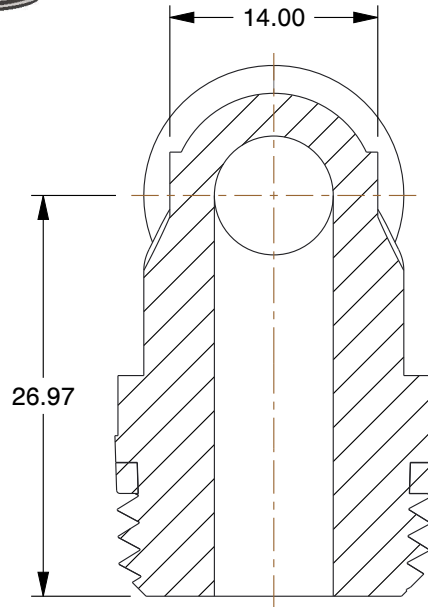


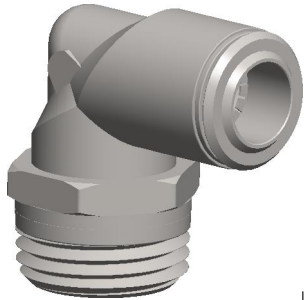

NOTES:

1. BASIC MATERIAL : Metal
2. BODY MATERIAL : Nickel Plated Brass
3. CONNECTION TYPE : Tube x Universal Thread
4. MAX. PRESSURE : 250 psi
5. TEMP. RANGE : 0° to 160°F
6. GASKET MATERIAL : Rubber
7. SPECIAL FEATURES : Universal Thread System Compatible with Inch and Metric Th

COMPONENT		Swivel Elbow, 90°	
1WUT9		UNIT	MM
		SHEET	1 of 1
		Swivel Elbow, 90 Deg, 10mm Tube Sz, PK3	

GRAINGER

100 Grainger Parkway, Lake Forest, Illinois 60045-5201
1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE 1.97