
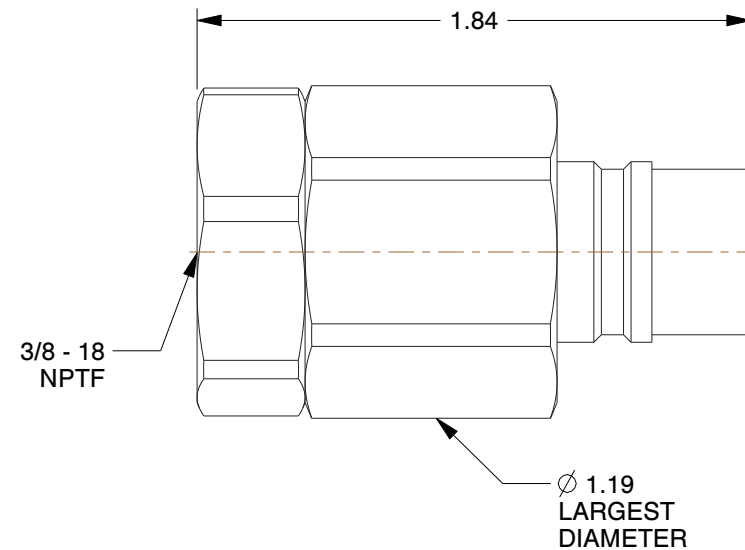


Series	H	Shut Off	Si
Sleeve Material	Brass	Valve Design	Poppet
Connection Type	FNPT	Seal Material	Buna
Coupler Body Size	3/8"	Max. Pressure	2250 psi
Coupler Flow Rate	13.0 gpm	Coupler Finish	Plain
Coupler Thread Size	3/8"-18	Locking Mechanism	Ball
Coupler Interchange Type	H	Coupler Body Material	Brass

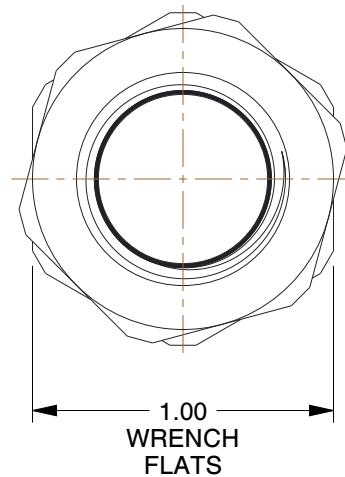

NOTES:

1. SEAL TYPE: Buna N
2. ITEM: Hydraulic Coupler Nipple
3. FOR USE WITH: Rubber Hose
4. OPERATING TEMP. RANGE: -40° to 200°F
5. QUICK COUPLER TYPE: Hydraulic Coupler Nipple

GRAINGER
/ / / / /

100 Grainger Parkway, Lake Forest, Illinois 60045-5201
1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE

1.57

COMPONENT	Hydraulic Quick Couplers		
20LF48 Coupler Nipple, 3/8-18, Body, Brass	UNIT		
	INCH		
	SHEET		
	1 of 1		