
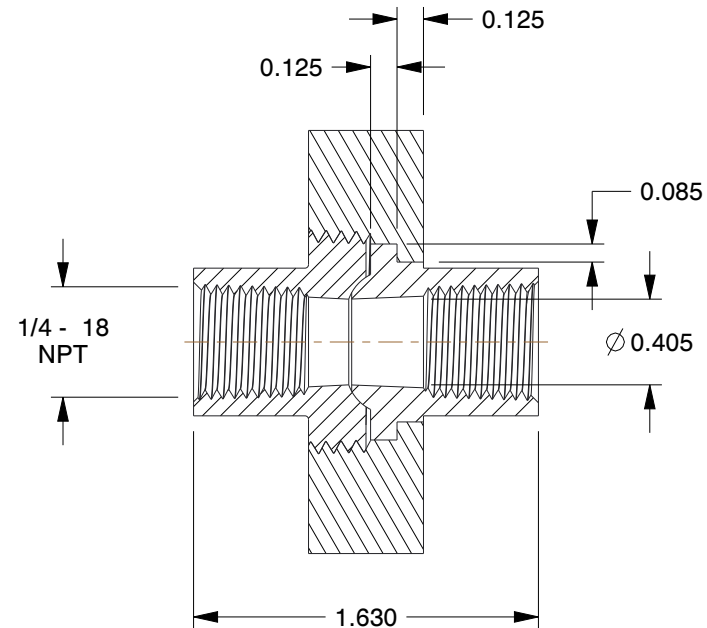
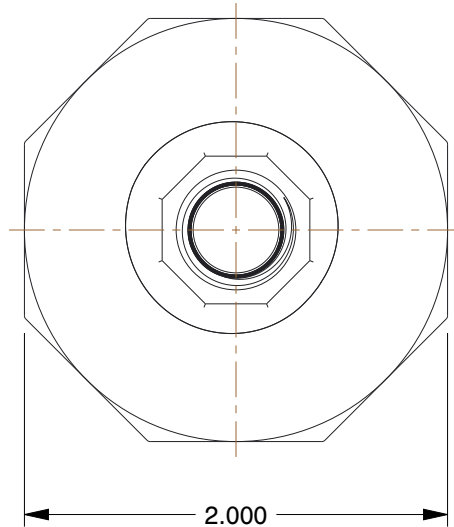


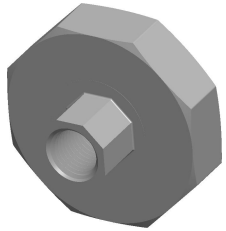

NOTES:

- ITEM: Union
- PIPE SIZE - PIPE FITTING: 1/4"
- MAX. PRESSURE: 2900 psi@100°F
- FITTING CONNECTION TYPE: FNPT
- PIPE FITTING MATERIAL: 304 Stainless Steel
- STANDARDS: Material Conforms To ASTM-A-182,
Threads Conform To ANSI/ASME B1.20.1 meets MSS SP-83

COMPONENT	Stainless Steel Pipe Fitting		
2UA95 Union, 1/4 In, Threaded, 304 SS	UNIT		
	INCH		
	SHEET		
	1 of 1		

GRAINGER

100 Grainger Parkway, Lake Forest, Illinois 60045-5201
1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE 1.10