
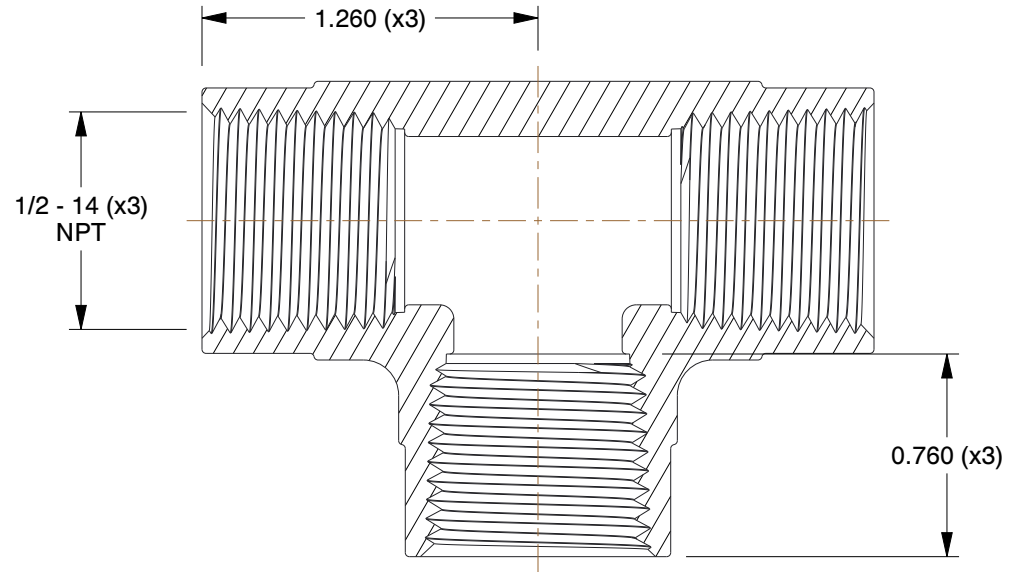


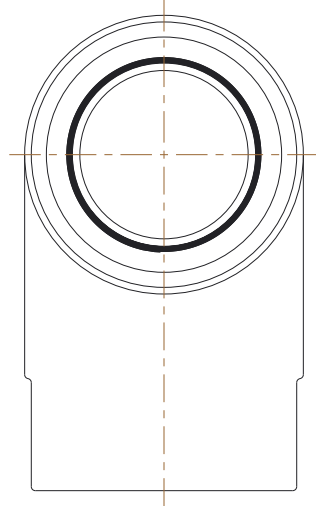

NOTES:

1. ITEM: Tee
2. COLOR: Gray
3. MAX. TEMP.: 210°F
4. PIPE SIZE - PIPE FITTING: 1/2"
5. PIPE FITTING MATERIAL: CPVC
6. MAX. PRESSURE: 424 psi @ 73°F
7. FITTING SCHEDULE/CLASS: Schedule 80
8. STANDARDS: ASTM D1784, NSF14 Certified
9. FITTING CONNECTION TYPE: FNPT x FNPT x FNPT

GRAINGER


100 Grainger Parkway, Lake Forest, Illinois 60045-5201
1-(800) GRAINGER, 1-(800) 472-4643, (847) 535-1000
www.grainger.com

This file and any associated information and specifications are provided for reference and evaluation purposes only, and is subject to change without notice. Grainger makes no representations, warranties or guarantees as to the appropriateness, accuracy, completeness, or suitability for any purpose, of the file, information or specifications. You are solely responsible for the use of the file, information or specifications.

This drawing is the property of GRAINGER. It contains confidential, proprietary information that is GRAINGER property. Do not disclose to or duplicate for others except as authorized by GRAINGER.

SCALE

1.39

COMPONENT	CPVC Pipe Fitting		
6ND55 Tee,CPVC,80,1/2 In.,FNPT,424 psi at 73F	UNIT		
	INCH		
	SHEET		
	1 of 1		